

1 Hole Offset Lug



FEATURES

Provides an efficient bolting surface for grounding and power applications

Electrolytic grade copper

For use with nVent ERICO Cadweld type LA connections only

SPECIFICATIONS

Table 1/3

Catalog Number	Material	Finish	Type	Height (H)	Length (L)	Width (W)
B101CEOL	Copper	Tinned	NEMA®	15.88 mm	63.5mm	25.4 mm
B101CEOL001	Copper	Tinned	NEMA®	15.88 mm	63.5mm	25.4 mm
B101QQOL	Copper	Tinned	NEMA®	15.87 mm	64mm	25.4 mm
B101DEOL	Copper	Tinned	NEMA®	17.53 mm	68.33mm	25.4 mm
B101SQOL	Copper	Tinned	NEMA®	14.26 mm	68mm	25.4 mm
B305SS	Stainless Steel 304 (EN 1.4301)		Non-NEMA®	20.07 mm	91.44mm	29.97 mm

CatalogNumber	Material	Finish	Type	Height (H)	Length (L)	Width (W)
B305TC	Copper	Tinned	Non-NEMA®	20 mm	91.4mm	30 mm
B101EEOL	Copper	Tinned	NEMA®	19.05 mm	76.2mm	25.4 mm
B101EFOL001	Copper	Tinned	NEMA®	19.05 mm	76.2mm	31.75 mm
B101EGOL	Copper	Tinned	NEMA®	19.05 mm	82.55mm	38.1 mm
B101GGOL	Copper	Tinned	NEMA®	31.75 mm	107.95mm	38.1 mm
B101GHOL	Copper	Tinned	NEMA®	31.75 mm	127mm	50.8 mm
B101GHOL001	Copper	Tinned	NEMA®	31.75 mm	127mm	50.8 mm

Table 2/3						
Catalog Number	Thickness (T)	A	B	C	Hole Size (HS)	Angle (a)
B101CEOL	3.18 mm	12.7 mm	25.4 mm	22.23 mm	11.11 mm	45 °
B101CEOL001	3.18 mm	12.7 mm	25.4 mm	22.23 mm	17.46 mm	45 °
B101QQOL	3.17 mm	12 mm	22 mm	19 mm	11.1 mm	45 °
B101DEOL	4.76 mm	14.3 mm	28.58 mm	22.23 mm	14.29 mm	45 °
B101SQOL	4.76 mm	14 mm	28 mm	20.5 mm	14.2 mm	45 °
B305SS	5.08 mm	15 mm	33.78 mm	39.88 mm	17 mm	45 °
B305TC	5 mm	15 mm	33.78 mm	39.88 mm	17 mm	45 °
B101EEOL	6.35 mm	15.9 mm	32.54 mm	26.92 mm	14.29 mm	45 °
B101EFOL001	6.35 mm	15.9 mm	32.54 mm	26.92 mm	17.46 mm	45 °
B101EGOL	6.35 mm	19.1 mm	38.1 mm	26.92 mm	17.46 mm	45 °

CatalogNumber	Thickness (T)	A	B	C	Hole Size (HS)	Angle (a)
B101GGOL	9.53 mm	19.1 mm	44.45 mm	38.1 mm	17.46 mm	45 °
B101GHOL	9.53 mm	25.4 mm	60.33 mm	38.1 mm	17.46 mm	45 °
B101GHOL001	9.53 mm	25.4 mm	60.33 mm	38.1 mm	20.64 mm	45 °


Table 3/3

Catalog Number	Equivalent Conductor Size
B101CEOL	80.63mm ²
B101CEOL001	80.63mm ²
B101QQOL	81mm ²
B101DEOL	120.94mm ²
B101SQOL	121mm ²
B305SS	152.23mm ²
B305TC	152.23mm ²
B101EEOL	161.26mm ²
B101EFOL001	201.57mm ²
B101EGOL	241.89mm ²
B101GGOL	362.83mm ²
B101GHOL	483.77mm ²
B101GHOL001	483.77mm ²

ADDITIONAL PRODUCT DETAILS

For sizes not listed, contact us.

DIAGRAMS

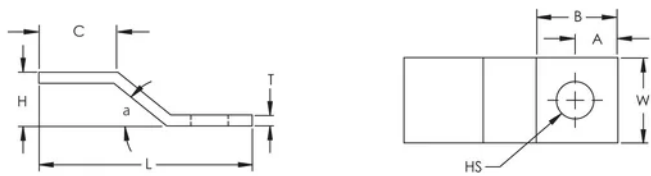

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE