


Non-Insulated Stranded Conductor, 10.7 mm dia, 70 mm², 70 mm² Stranded

CATALOG NUMBER

SCEC70

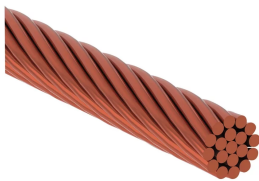

FEATURES

Stranded pure electrolytic copper cable conductors for a variety of applications

Stranded grounded conductor cut into standard lengths for easy field installation

PRODUCT ATTRIBUTES

Article Number: 197930

Material: Copper

Conductor Type: Concentric

Number of Wires: 19

Wire Diameter: 2.14mm

Diameter (Ø): 10.69 mm

Length (L): 500m

Cross Section: 70mm²


Conductor Size: 70 mm² Stranded

Unit Weight: 31 kg

ADDITIONAL PRODUCT DETAILS

Outer diameter dimensions are approximate.

DIAGRAMS

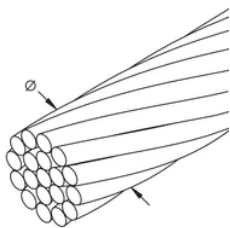

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE