

Glazing Bar Holdfast



FEATURES

For bonding window frames and other metallic structural features

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Flange Thickness (FT)	Screw Diameter (Sc)	Depth (D)	Height (H)
GBHA	710305	Aluminum	13 mm Max	6	20mm	20 mm
GBHC	710300	Bronze	13 mm Max	6	20mm	20 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Unit Weight
GBHA	710305	33 mm	0.04 kg
GBHC	710300	33 mm	0.04 kg

DIAGRAMS

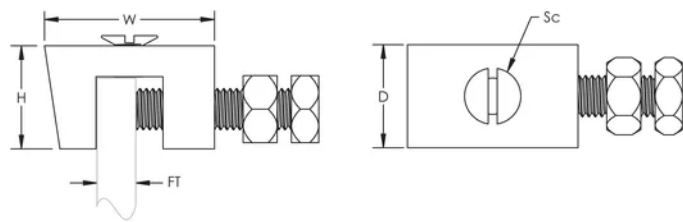

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE