

EM-M Conduit/Pipe to Flange Clip



CERTIFICATIONS



FEATURES

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)	Static Load
8EM24S1	179780	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	3 - 8 mm	200N
16EM24	171740	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	3 - 8 mm	330N
20EM24	171800	Spring Steel	nVent CADDY Armour	35 - 42 mm	3 - 8 mm	330N
24EM24	171960	Spring Steel	nVent CADDY Armour	42 - 50 mm	3 - 8 mm	330N

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)	Static Load
32EM24	173600	Spring Steel	nVent CADDY Armour	50 - 60 mm	3 - 8 mm	330N
812EM24	160120	Spring Steel	nVent CADDY Armour	18 - 30 mm	3 - 8 mm	330N
12EM58S1	179820	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	8 - 14 mm	200N
16EM58	171490	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	8 - 14 mm	330N
20EM58	171950	Spring Steel	nVent CADDY Armour	35 - 42 mm	8 - 14 mm	330N
24EM58	171970	Spring Steel	nVent CADDY Armour	42 - 50 mm	8 - 14 mm	330N
32EM58	173610	Spring Steel	nVent CADDY Armour	50 - 60 mm	8 - 14 mm	330N
6EM58	171750	Spring Steel	nVent CADDY Armour	14 - 18 mm	8 - 14 mm	330N
812EM58	160130	Spring Steel	nVent CADDY Armour	18 - 30 mm	8 - 14 mm	330N
8EM58S1	179790	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	8 - 14 mm	200N
12EM912S1	179830	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	14 - 20 mm	200N
16EM912	173570	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	14 - 20 mm	330N
20EM912	173580	Spring Steel	nVent CADDY Armour	35 - 42 mm	14 - 20 mm	330N
24EM912	173590	Spring Steel	nVent CADDY Armour	42 - 50 mm	14 - 20 mm	330N
32EM912	173620	Spring Steel	nVent CADDY Armour	50 - 60 mm	14 - 20 mm	330N
812EM912	160140	Spring Steel	nVent CADDY Armour	18 - 30 mm	14 - 20 mm	330N
8EM912S1	179800	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	14 - 20 mm	200N


CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)	Static Load
812EM1318	160075	Spring Steel	nVent CADDY Armour	18 - 30 mm	21 - 28 mm	330N
16EM1318	173745	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	21 - 28 mm	330N

Table 2/2

Catalog Number	Article Number	Certifications
8EM24S1	179780	
16EM24	171740	ITB
20EM24	171800	ITB
24EM24	171960	ITB
32EM24	173600	ITB
812EM24	160120	ITB
12EM58S1	179820	
16EM58	171490	ITB
20EM58	171950	ITB
24EM58	171970	ITB
32EM58	173610	ITB
6EM58	171750	
812EM58	160130	ITB
8EM58S1	179790	
12EM912S1	179830	

Catalog Number	Article Number	Certifications
16EM912	173570	ITB
20EM912	173580	ITB
24EM912	173590	ITB
32EM912	173620	ITB
812EM912	160140	ITB
8EM912S1	179800	
812EM1318	160075	cUL, UL
16EM1318	173745	cUL, UL

DIAGRAMS

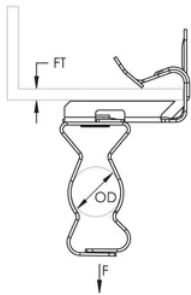

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

