

Air Terminal Base, Stamped Ridge Mount, Imperial Thread



CERTIFICATIONS



FEATURES

For use on ridged roofs

For positive bolt tension cable clamping

SPECIFICATIONS


Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Material: Copper

Table 1/1

Catalog Number	Thread Size (TS)	Hole Size (HS)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPC31258	5/8" UNC	5.08 mm	63.5mm	43.81 mm	304.8 mm	0.43 kg
LPC31212	1/2" UNC	5.08 mm	63.5mm	43.81 mm	304.8 mm	0.43 kg

DIAGRAMS

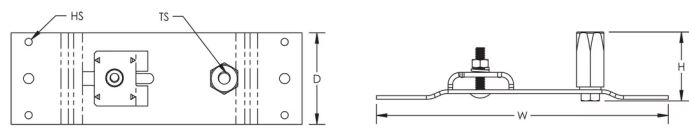

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE