


CPCI Power Backplane With P 47 Connector

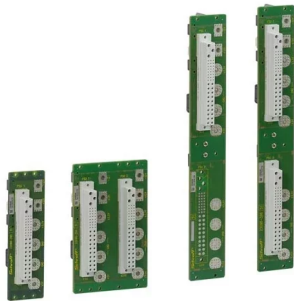

Power Backplane for CompactPCI Applications. With P47 Power Connector.

CERTIFICATIONS



FEATURES

In accordance with: PICMG 2.11 R1.0 CompactPCI Power Interface specification

In accordance with: PICMG 2.9 R1.0 System Management Bus specification

Single, parallel or redundant operation possible

Geographical address adjustable

Power supply over crimp contacts inserted into the plug, no supply voltage on the backplane

Power cable available as an accessory

DC outlets with powerbugs for extremely low drops in voltage

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-393	Backplane	1	3U	CompactPCI Power Backplane with P47	8HP	

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	Slot Width	ConnectorType
23098-394	Backplane	2	3U	CompactPCI Power Backplane with P47	8HP	P47
23098-395	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	
23098-396	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	

Table 2/2

Catalog Number	Power Connector Type	Utility Connector Type	Width	Package Quantity	Quick Ship
23098-393	(1) P47	SMCQ, 12-pin, MicroMatch, 10- pin	39.6mm	1	No
23098-394	(2) P47	SMCQ, 12-pin, MicroMatch, 10- pin	80.3mm	1	No
23098-395	(1) P47	SMCQ, 12-pin, MicroMatch, 10- pin	39.6mm	1	No
23098-396	(2) P47	SMCQ, 12-pin, MicroMatch, 10- pin	39.6mm	1	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE