


# nVent CADDY Macrofix Plus Kombi with Combination Nut

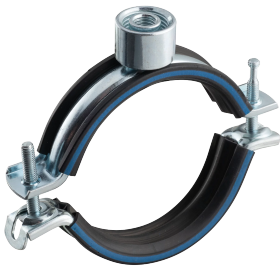

## FEATURES

Includes easy closing mechanism

Age-resistant lining

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

|                       |                       |
|-----------------------|-----------------------|
| <b>Rod Size (RS):</b> | M8;M10;1/2"           |
| <b>Temperature:</b>   | -50 to 110 °C         |
| <b>Color:</b>         | Black                 |
| <b>Finish:</b>        | Electrogalvanized     |
| <b>Material:</b>      | Steel;EPDM-SBR Rubber |

Table 1/2

| Catalog Number | Article Number | Outer Diameter (OD) | NB/DN | Width (W) | Thickness (T) | Screw Diameter (Sc) |
|----------------|----------------|---------------------|-------|-----------|---------------|---------------------|
| MPK037         | 586755         | 31 - 37 mm          | 25    | 20 mm     | 1 mm          | 6 mm                |
| MPK031         | 586754         | 25 - 31 mm          | 20    | 20 mm     | 1 mm          | 6 mm                |

| CatalogNumber | Article Number | Outer Diameter (OD) | NB/DN | Width (W) | Thickness (T) | ScrewDiameter (Sc) |
|---------------|----------------|---------------------|-------|-----------|---------------|--------------------|
| MPK044        | 586756         | 37 - 44 mm          | 32    | 20 mm     | 1 mm          | 6 mm               |
| MPK051        | 586757         | 45 - 51 mm          | 40    | 21 mm     | 1.25 mm       | 6 mm               |
| MPK068        | 586759         | 58 - 68 mm          | 50    | 21 mm     | 1.25 mm       | 6 mm               |
| MPK058        | 586758         | 50 - 58 mm          |       | 21 mm     | 1.25 mm       | 6 mm               |
| MPK078        | 586760         | 68 - 78 mm          | 65    | 23 mm     | 1.5 mm        | 6 mm               |
| MPK088        | 586761         | 78 - 88 mm          |       | 23 mm     | 1.5 mm        | 6 mm               |
| MPK098        | 586762         | 88 - 98 mm          | 80    | 23 mm     | 1.75 mm       | 6 mm               |
| MPK118        | 586763         | 108 - 118 mm        | 100   | 23 mm     | 1.75 mm       | 6 mm               |
| MPK170        | 586767         | 160 - 170 mm        | 150   | 25 mm     | 2 mm          | 6 mm               |
| MPK148        | 586765         | 138 - 148 mm        | 125   | 25 mm     | 2 mm          | 6 mm               |
| MPK160        | 586766         | 150 - 160 mm        |       | 25 mm     | 2 mm          | 6 mm               |
| MPK138        | 586764         | 128 - 138 mm        |       | 23 mm     | 2 mm          | 6 mm               |
| MPK201        | 586768         | 190 - 200 mm        |       | 27 mm     | 2.25 mm       | 6 mm               |

Table 2/2


| Catalog Number | Article Number | Screw Length (L) | Static Load | Unit Weight |
|----------------|----------------|------------------|-------------|-------------|
| MPK037         | 586755         | 32mm             | 1000N       | 0.12 kg     |
| MPK031         | 586754         | 32mm             | 1000N       | 0.11 kg     |
| MPK044         | 586756         | 37mm             | 1000N       | 0.12 kg     |
| MPK051         | 586757         | 37mm             | 1500N       | 0.14 kg     |

| Catalog Number | Article Number | Screw Length (L) | Static Load | Unit Weight |
|----------------|----------------|------------------|-------------|-------------|
| MPK068         | 586759         | 40mm             | 1500N       | 0.16 kg     |
| MPK058         | 586758         | 37mm             | 1500N       | 0.15 kg     |
| MPK078         | 586760         | 40mm             | 2000N       | 0.19 kg     |
| MPK088         | 586761         | 40mm             | 2000N       | 0.2 kg      |
| MPK098         | 586762         | 45mm             | 2500N       | 0.27 kg     |
| MPK118         | 586763         | 50mm             | 2500N       | 0.3 kg      |
| MPK170         | 586767         | 50mm             | 3200N       | 0.42 kg     |
| MPK148         | 586765         | 50mm             | 3200N       | 0.4 kg      |
| MPK160         | 586766         | 50mm             | 3200N       | 0.42 kg     |
| MPK138         | 586764         | 50mm             | 3000N       | 0.34 kg     |
| MPK201         | 586768         | 50mm             | 3600N       | 0.63 kg     |

## ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

## DIAGRAMS

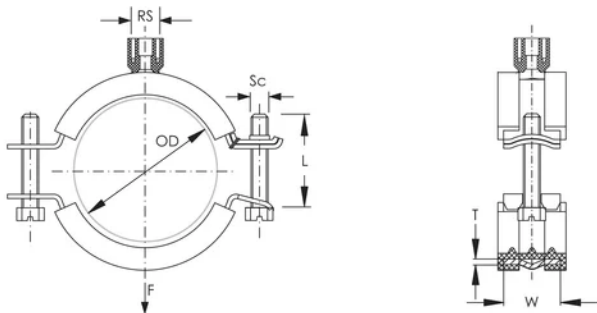

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

