


# SIM Stainless Steel Mast

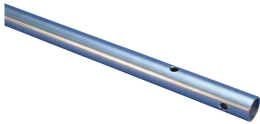

## FEATURES

Designed to mount Early Streamer Emitter air terminals

Mounts conventional air terminals with appropriate adaptor

## SPECIFICATIONS

Table 1/2

Catalog Number	Material	Product	Thread Size (TS)	Length (L)	Thickness (T)	Outer Diameter (OD)
SIM28A2	Stainless Steel 304L (EN 1.4306)	Upper Mast Section	M25	2000mm	2 mm	28 mm
SIM28A2316	Stainless Steel 316L (EN 1.4404)	Upper Mast Section	M25	2000mm	2 mm	28 mm
SIM33B2	Stainless Steel 304L (EN 1.4306)	Mid Mast Section		2000mm	2.5 mm	33 mm
SIM33B2316	Stainless Steel 316L (EN 1.4404)	Mid Mast Section		2000mm	2.5 mm	33 mm
SIM33B3	Stainless Steel 304L (EN 1.4306)	Mid Mast Section		3000mm	2.5 mm	33 mm
SIM33B3316	Stainless Steel 316L (EN 1.4404)	Mid Mast Section		3000mm	2.5 mm	33 mm


CatalogNumber	Material	Product	Thread Size (TS)	Length (L)	Thickness (T)	Outer Diameter (OD)
SIM40C2	Stainless Steel 304L (EN 1.4306)	Lower Mast Section		2000mm	2.5 mm	40 mm
SIM40C3	Stainless Steel 304L (EN 1.4306)	Lower Mast Section		3000mm	2.5 mm	40 mm
SIM40C2316	Stainless Steel 316L (EN 1.4404)	Lower Mast Section		2000mm	3.55 mm	42.4 mm
SIM40C3316	Stainless Steel 316L (EN 1.4404)	Lower Mast Section		3000mm	3.55 mm	42.4 mm

Table 2/2

Catalog Number	Hardware Included	Unit Weight
SIM28A2	No	2.3 kg
SIM28A2316	No	2.3 kg
SIM33B2	Yes	3.5 kg
SIM33B2316	Yes	3.5 kg
SIM33B3	Yes	5.3 kg
SIM33B3316	Yes	5.3 kg
SIM40C2	Yes	4 kg
SIM40C3	Yes	6.05 kg
SIM40C2316	Yes	6.93 kg
SIM40C3316	Yes	10.4 kg

## DIAGRAMS

 ---



## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**