


Frame Type Plug-In Unit Front Panel, Unshielded, 6 U, 12 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

CATALOG NUMBER

34812-612

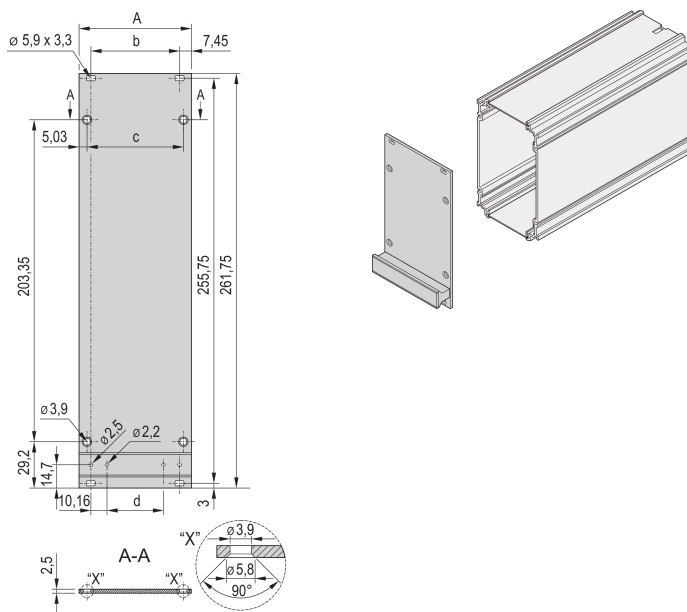

Front Panel for frame type plug-in unit, shieldable.

CERTIFICATIONS



FEATURES

Al, 2.5 mm, front anodized, rear anodized, cut edges blank

Front Panel for frame type plug-in units PRO

PRODUCT ATTRIBUTES


Rack Width: 12HP
Accessory Type: Front panel
Package Quantity: 1
Front Finish: Anodized
Rear Finish: Conductive
Treated Edges: No
Depth (D): 2.5mm
Finish: Anodized
Height (H): 261.75mm
Material: Aluminum
Product Type: Front Panel
Rack Height: 6U
Width (W): 60.62mm
Net Weight: 0.1kg

ADDITIONAL PRODUCT DETAILS

Mounting kit to fix front Panel to plug-in unit, handle to bolt on, clip and screw with plastic sleeve for mounting plug-in unit in subrack or case are included in the item 'Mounting kit for five plug-in units', part number 24812-100. The handle is available in 2 colors (grey or black). Individual parts 100 pieces. Screw for fixing front Panel to plug-in unit, part no. 24812-501. Screw for mounting handle, part no. 24560-179 Clip - mounting aid for handle, part no. 21101-239. Screw for sleeve, threaded insert front inserted into horizontal rail, part no. 21100-748. Screw for sleeve, threaded insert rear inserted into horizontal rail, part no. 21101-101. Sleeve 21100-660, 21100-661, 21100 - 662, 21100-886, 21100-146.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

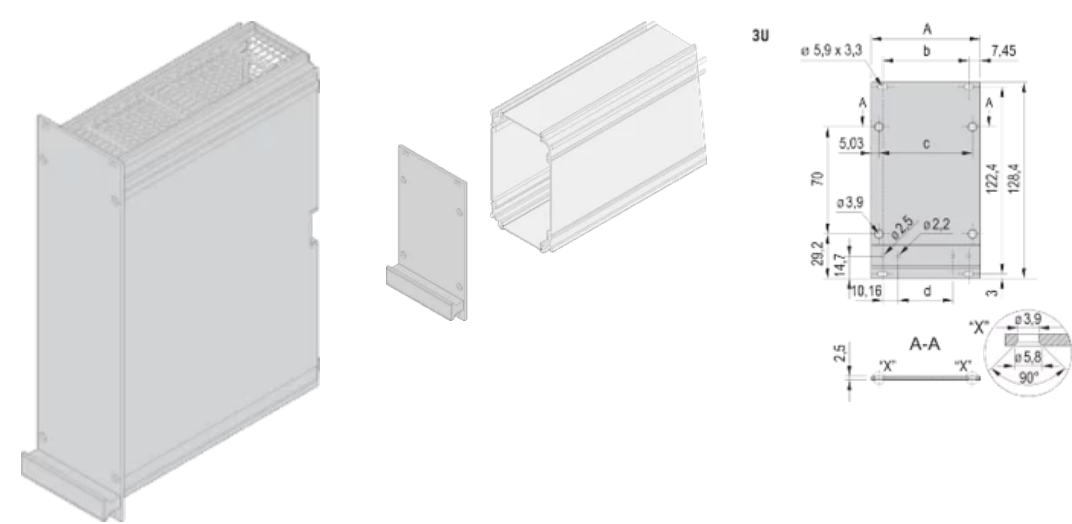

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE