


Novastar Glass Door, 180° Opening Angle

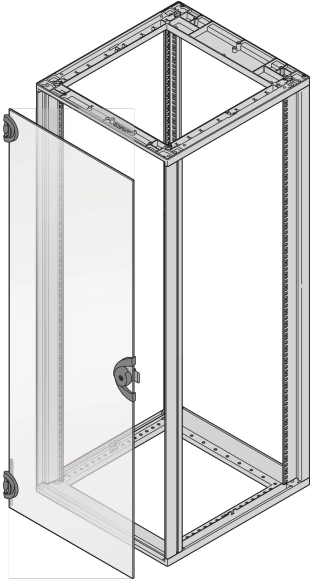

Glazed / Glass doors for aluminum frame cabinets with attractive design, ideally suited for general electronics, test & measurement, audio/video and broadcasting applications.

CERTIFICATIONS



FEATURES

Glass type: ESG 6 mm, EN 12150

Opening angle 180°

Lock with key

Can be assembled at front and rear

SPECIFICATIONS

Product Type: Cabinet Door

Material: Reinforced Polycarbonate

Table 1/2

Catalog Number	Rack Height	Height	Width	Package Quantity	Color	Color Code
27230-001	6U	323mm	553mm	1	Light Grey	RAL 7035
27230-002	9U	422mm	553mm	1	Light Grey	RAL 7035
27230-003	12U	555mm	553mm	1	Light Grey	RAL 7035
27230-004	16U	733mm	553mm	1	Light Grey	RAL 7035
27230-005	20U	911mm	553mm	1	Light Grey	RAL 7035
27230-006	25U	1133mm	553mm	1	Light Grey	RAL 7035
27230-007	34U	1534mm	553mm	1	Light Grey	RAL 7035
27230-008	38U	1711mm	553mm	1	Light Grey	RAL 7035
27230-009	43U	1933mm	553mm	1	Light Grey	RAL 7035
27230-010	47U	2111mm	553mm	1	Light Grey	RAL 7035
27230-028	29U	1345mm	553mm	1	Light Grey	RAL 7035

Table 2/2

Catalog Number	Finish	Type	Quick Ship
27230-001		Glass Door	No
27230-002		Glass Door	No
27230-003		Glass Door	No
27230-004		Glass Door	No
27230-005		Glass Door	No

Catalog Number	Finish	Type	Quick Ship
27230-006		Glass Door	No
27230-007		Glass Door	No
27230-008		Glass Door	No
27230-009		Glass Door	No
27230-010		Glass Door	No
27230-028	Powder Coated	Glass Door	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE