


## Varistar CP Swing Frame for 800 mm Width

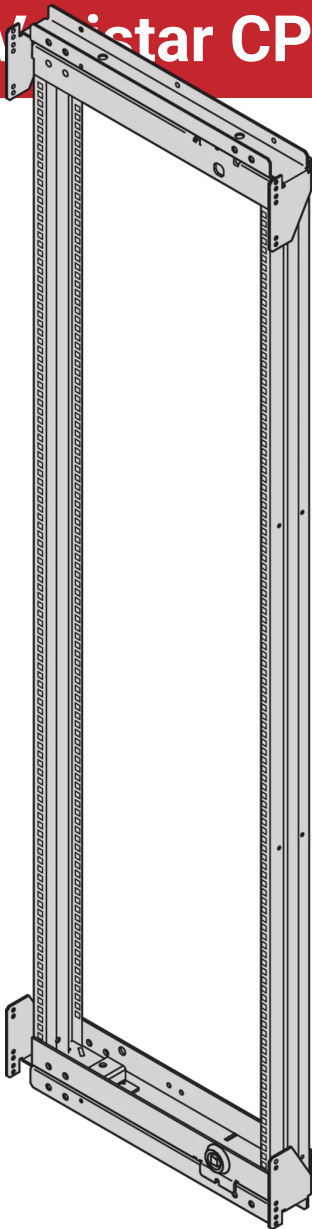

The 19" swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° / 160° movement and flexible pivot point.

### FEATURES

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks

120° / 160° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

Usable height within the swing frame is 4U lesser than the frame height to which the swing frame is attached to.

## SPECIFICATIONS

**Width:** 800mm  
**Product Type:** Cabinet/Rack Frame  
**Material:** Steel

Table 1/2

Catalog Number	Angle	Rack Height	Package Quantity	Color	Color Code	Finish
21630-669	120° min	24U	1	Black Grey	RAL 7021	Powder Coated
21630-671	120° min	29U	1	Black Grey	RAL 7021	Powder Coated
21630-673	120° min	33U	1	Black Grey	RAL 7021	Powder Coated
21630-675	120° min	38U	1	Black Grey	RAL 7021	Powder Coated
21630-677	120° min	42U	1	Black Grey	RAL 7021	Powder Coated
21630-679	120° min	47U	1	Black Grey	RAL 7021	Powder Coated
21630-680	160° min	24U	1	Black Grey	RAL 7021	Powder Coated
21630-681	160° min	29U	1	Black Grey	RAL 7021	Powder Coated
21630-682	160° min	33U	1	Black Grey	RAL 7021	Powder Coated
21630-683	160° min	38U	1	Black Grey	RAL 7021	Powder Coated
21630-684	160° min	42U	1	Black Grey	RAL 7021	Powder Coated
21630-685	160° min	47U	1	Black Grey	RAL 7021	Powder Coated

Table 2/2

Catalog Number	Height	Protection Rating	Quick Ship
21630-669	1200mm	IP20	No

Catalog Number	Height	Protection Rating	Quick Ship
21630-671	1400mm	IP20	No
21630-673	1600mm	IP20	No
21630-675	1800mm	IP20	No
21630-677	2000mm	IP20	No
21630-679	2200mm	IP20	No
21630-680	1200mm	IP20	No
21630-681	1400mm	IP20	No
21630-682	1600mm	IP20	No
21630-683	1800mm	IP20	No
21630-684	2000mm	IP20	No
21630-685	2200mm	IP20	No

## ADDITIONAL PRODUCT DETAILS

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**