


nVent LENTON Speed Sleeve Transition Adaptor

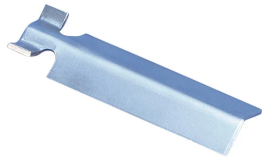

nVent LENTON Speed Sleeve Transition Adaptors allow the nVent LENTON Speed Sleeve to be used as a transition splice. The transition adaptors are simply placed inside the sleeve underneath the straps of the smaller bar end.

CARACTERÍSTICAS

Bars can be individually secured

Fast, one-man installation

Requires only a lightweight ratchet wrench to install

Can be used to splice two smaller bars

ESPECIFICACIONES

Acabado: Claro

Material: Acero

Table 1/1

Número de catálogo	Número de artículo	Longitud (L)	Anchura (W)	Peso por unidad	Cantidad del paquete
RBW3997		86mm	27 mm	0.03 kg	20
RBW3998		86mm	29 mm	0.04 kg	20
RBW3999	145565	86mm	38 mm	0.04 kg	20
RBW39910		111mm	38 mm	0.05 kg	20


Número de catálogo	Número de artículo	Longitud (L)	Anchura (W)	Peso por unidad	Cantidad del paquete
RBW39911		146mm	51 mm	0.11 kg	20
RBW39914		152mm	57 mm	0.32 kg	10

DETALLES ADICIONALES DEL PRODUCTO

nVent LENTON Speed Sleeve is a compression-only splicing system. It should never be used for tension applications.

LENTON SPEED SLEEVE Transition Adaptors					
Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Sleeve	Adaptor	Adaptors Required
25 to 22 mm	#8 to #7	-	RBW2688	RBW3997	1
28 to 25 mm	#9 to #8	-	RBW2689	RBW3998	1
32 to 28 mm	#10 to #9	-	RBW26810	RBW3999	1
36 to 32 mm	#11 to #10	35M to 30M	RBW26811	RBW39910	1
43 to 36 mm	#14 to #11	45M to 35M	RBW26814	RBW39911	2
57 to 43 mm	#18 to #14	55M to 45M	RBW26818	RBW39914	2

 DIAGRAMAS



ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

Norteamérica

+1.800.753.9221

Opción 1: Atención al
cliente

Opción 2: Soporte técnico

Europa

Países Bajos:

+31 800-0200135

Francia:

+33 800 901 793

Europa

Alemania:

800 1890272

Otros países:

+31 13 5835404

Asia-Pacífico

Shanghái:

+86 21 2412 1618/19

Sídney:

+61 2 9751 8500



Nuestra poderosa cartera de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE