


Novastar Base/Plinth

Servicios públicos de energía

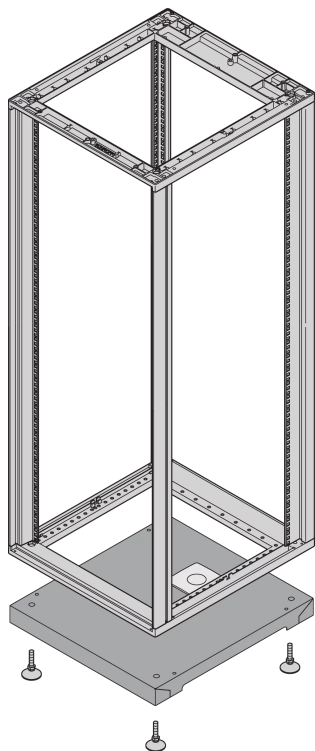

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

CERTIFICACIONES



CARACTERÍSTICAS

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

ESPECIFICACIONES

Table 1/2						
Número de catálogo	Ancho	Profundidad	Color	Color Code	Altura	Product Type
27230-070	553 mm	500 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-071	553 mm	600 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-072	553 mm	800 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-076	900 mm	900 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-080	1000 mm	1000 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base

Table 2/2	
Número de catálogo	Tipo
27230-070	Base Plinth
27230-071	Base Plinth
27230-072	Base Plinth
27230-076	Base Plinth
27230-080	Base Plinth

ADDITIONAL PRODUCT DETAILS

Please order brush strip separately.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE