


Front Panel, Flat, Unshielded, D-Sub Cutouts

Servicios públicos de energía

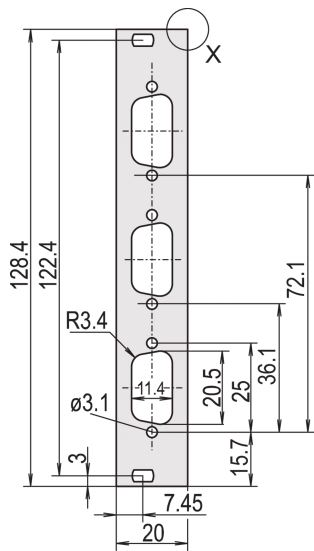

Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFICACIONES



CARACTERÍSTICAS

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

ESPECIFICACIONES

Table 1/3						
Número de catálogo	Package Quantity	Montaje	Front Finish	Rear Finish	Treated Edges	Cumple con
30118-341	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10

Número de catálogo	Package Quantity	Montaje	Front Finish	Rear Finish	Treated Edges	Cumple con
30118-342	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-343	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-344	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-345	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-346	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10
30118-347	5	Screw-on Front	Anodizado	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Número de catálogo	EMC Shielding	Altura	Material	Product Type	Rack Height	Rack Width
30118-341	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP
30118-342	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP
30118-343	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP
30118-344	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP
30118-345	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP
30118-346	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP
30118-347	No	128.4 mm	Aluminio	Front Panel	3 U	4 HP

Table 3/3

Número de catálogo	Tipo	Ancho
30118-341	Front Panel without Handle	20 mm

Número de catálogo	Tipo	Ancho
30118-342	Front Panel without Handle	20 mm
30118-343	Front Panel without Handle	20 mm
30118-344	Front Panel without Handle	20 mm
30118-345	Front Panel without Handle	20 mm
30118-346	Front Panel without Handle	20 mm
30118-347	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE