


# MultipacPRO 19" Chassis, Steel, AlZn, Plain Top and Base

## Servicios públicos de energía

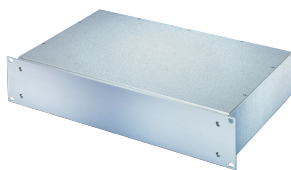

This 19" chassis is a form of subrack which accepts horizontal board mounting or the mounting of non-standard components like transformers or other heavy load accessories typically mounted on a chassis plate. This version is produced from sheet metal, Al-Zn coated and have plain top and bottom covers.

### CERTIFICACIONES



### CARACTERÍSTICAS

Steel (AlZn coated) with Al extrusion front panel

Detachable front and rear panel for easy machining

IP 20, in accordance with IEC 60529

Supplied as space-saving flat-pack

EMC shielding: Approx. 20dB(A) at 2GHz without shielding material. >40dB(A) at 1Ghz with addition of stainless steel gasket between front panel and case body

Internal and external dimensions in accordance with: IEC 60297-3-101

EMC shielding: Approx. 20dB(A) at 2 GHz without shielding material. >40dB(A) at 1 GHz with addition of stainless steel gasket between front panel and case body

### ESPECIFICACIONES

Table 1/2

| Número de catálogo | Rack Height | Profundidad | Usable Width | Montaje | Cumple con                       | EMC Shielding      |
|--------------------|-------------|-------------|--------------|---------|----------------------------------|--------------------|
| 20860-120          | 1 U         | 220 mm      | 447 mm       | Rack    | IEC 60297-3-100, IEC 60297-3-105 | No (Retrofittable) |
| 20860-121          | 1 U         | 280 mm      | 447 mm       | Rack    | IEC 60297-3-100, IEC 60297-3-105 | No (Retrofittable) |
| 20860-122          | 1 U         | 340 mm      | 447 mm       | Rack    | IEC 60297-3-100, IEC 60297-3-105 | No (Retrofittable) |
| 20860-126          | 2 U         | 280 mm      | 447 mm       | Rack    | IEC 60297-3-100                  | No (Retrofittable) |
| 20860-127          | 2 U         | 340 mm      | 447 mm       | Rack    | IEC 60297-3-100                  | No (Retrofittable) |

Table 2/2

| Número de catálogo | Product Family | Product Type    | Tipo   |
|--------------------|----------------|-----------------|--------|
| 20860-120          | MultipacPRO    | Subrack/Chassis | Rígido |
| 20860-121          | MultipacPRO    | Subrack/Chassis | Rígido |
| 20860-122          | MultipacPRO    | Subrack/Chassis | Rígido |
| 20860-126          | MultipacPRO    | Subrack/Chassis | Rígido |
| 20860-127          | MultipacPRO    | Subrack/Chassis | Rígido |

## ADDITIONAL PRODUCT DETAILS

Please order front handles separately.

Telescopic slides cannot be used.

Further versions with steel front panel (pizza box) available on request.

Standardised internal mounting kits cannot be used.

## ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en [www.nvent.com](http://www.nvent.com) y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento

completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**