


EuropacPRO 19" Subrack Kit for Railway, Shielded, SNCF, CompactPCI

Power Utilities

Subrack for Railway applications, conform to SNCF Standard, shielded version for CompactPCI applications.

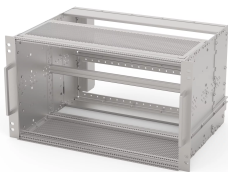

CERTIFICACIONES



CARACTERÍSTICAS

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

ESPECIFICACIONES

Table 1/3						
Número de catálogo	Altura del rack	Ancho del rack	Cantidad del paquete	Para montaje	Profundidad de la placa	Tipo de junta EMC
21500-072	6 U	36 HP	1	Plano trasero	160 mm	Textil
21500-069	3 U	36 HP	1	Plano trasero	160 mm	Textil
21500-047	3 U	84 HP	1	Plano trasero	160 mm	Textil
21500-046	6 U	84 HP	1	Plano trasero	160 mm	Textil

Table 2/3						
Número de catálogo	Tolerancia a impactos y vibraciones	Mango incluido	Montaje	De conformidad con	Fondo	Apantallamiento EMC
21500-072	5 g (force)	Sí	Rack	IEC 60297-3-103, IEEE 1101,10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí
21500-069	5 g (force)	Sí	Rack	IEC 60297-3-103, IEEE 1101,10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí
21500-047	5 g (force)	Sí	Rack	IEC 60297-3-103, IEEE 1101,10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí
21500-046	5 g (force)	Sí	Rack	IEC 60297-3-103, IEEE 1101,10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí

Table 3/3			
Número de catálogo	Tipo de producto	Carga estática	Certificaciones

21500-072	Subrack/chasis	15 kgf	RoHS
21500-069	Subrack/chasis	15 kgf	RoHS
21500-047	Subrack/chasis	15 kgf	RoHS, SNCF
21500-046	Subrack/chasis	15 kgf	RoHS, SNCF

DETALLES ADICIONALES DEL PRODUCTO

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Version 9 T available on request; Test reports available online.

Guide rails color according to IEEE 1101.10 red = space for CPU-board; grey = space for peripheral boards; green = space for CompactPCI; 19"-power supplies 0,1" offset.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Nuestro gran portafolio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE