


EuropacPRO 19" Subrack Kit for Railway, Shielded, SNCF

Servicios públicos de energía

Subrack for Railway applications, conform to SNCF Standard.

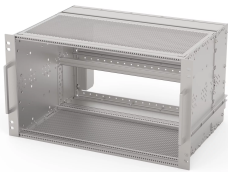

CERTIFICACIONES



CARACTERÍSTICAS

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

ESPECIFICACIONES

Table 1/3						
Número de catálogo	Rack Height	Rack Width	Package Quantity	For Mounting	Board Depth	EMC Gasket Type
21500-071	6 U	36 HP	1	Backplane	220 mm	Textile
21500-068	3 U	36 HP	1	Backplane	220 mm	Textile
21500-030	3 U	84 HP	1	Backplane	220 mm	Textile
21500-028	6 U	84 HP	1	Backplane	220 mm	Textile

Table 2/3						
Número de catálogo	Shock and Vibration Tolerance	Handle Included	Montaje	Cumple con	Profundidad	EMC Shielding
21500-071	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí
21500-068	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí
21500-030	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí
21500-028	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	320 mm	Sí

Table 3/3			
Número de catálogo	Product Type	Carga estática	Certificaciones
21500-071	Subrack/Chassis	15 kgf	RoHS
21500-068	Subrack/Chassis	15 kgf	RoHS
21500-030	Subrack/Chassis	15 kgf	RoHS, SNCF

Número de catálogo	Product Type	Carga estática	Certificaciones
21500-028	Subrack/Chassis	15 kgf	RoHS, SNCF

ADDITIONAL PRODUCT DETAILS

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE