


Cable Entry Gld Plt Grommet Small, CCFGs B, 20x20x18mm, GY, Plastic

NÚMERO DE CATÁLOGO

CCFGSB

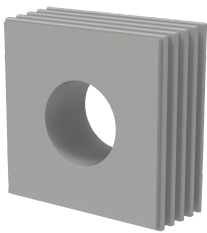

CCFGS cable glands are used with CCFI, CCFO and CCFR cable entry systems.

ESTÁNDARES DEL SECTOR

Inflamabilidad UL94 V-0

UL94 V-0 Flammability

NEMA tipo 1, 12, 4X (sólo interiores)

CE

IP66

CARACTERÍSTICAS

0

Everything mounted from the outside of the enclosure

The frames, inlays and grommets can be combined in many ways - ensuring you many versatile configuration options

The frame does not need to be disassembled if requirements change or carrying out service work

No need to disassemble and reconnect connectors on cables so manufactures warranty is not voided

The conical shape of the grommets allows them to be easily pressed in, provides static strain relief in accordance with DIN EN 62444

For assembly, they are pressed from the inside out into the openings of the assembled inlays

The grommets are available in different sizes to match the diameter of the cable

The CCFGs is first placed around the cable and then inserted into the cable gland

Based on the wave-cut profile, there is no need to remove the connector on the assembled cabled

ATRIBUTOS DEL PRODUCTO

Número de artículo: 58335

Altura: 20.3mm

Anchura: 20mm

Fondo: 17.7mm

Material: De plástico

Acabado: Sin tratamiento

Color: Gris

Temperatura de funcionamiento: -40 to 90°C

Peso: 0.00770975056689342kg

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

©2025 nVent. Todas las marcas y logotipos de nVent son propiedad de nVent Services GmbH o sus filiales, o se utilizan bajo su licencia. El resto de las marcas comerciales son propiedad de sus respectivos propietarios. nVent se reserva el derecho a cambiar las especificaciones sin previo aviso.

Este documento lo ha generado el sistema.