


Panel Frontal, Blindaje Refrofit, 3 U, 84 HP, 2,5 mm, AL, Anodizado delantero, Conductor trasero

NÚMERO DE CATÁLOGO

30846-676

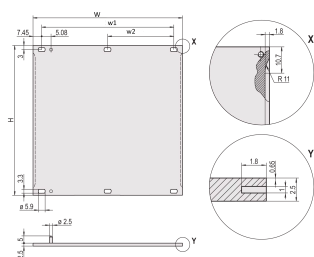

Panel frontal plano. Blindable con junta EMC de acero inoxidable.

CERTIFICACIONES



CARACTERÍSTICAS

Para acero inoxidable EMC junta

Al, 2,5 mm, anodizado frontal, conductor

ATRIBUTOS DEL PRODUCTO

Altura del rack: 3U

Ancho del rack: 84HP

Cantidad del paquete: 1

Tipo de accesorio: Panel frontal

Montaje: Atornillado delantero

Tipo de junta EMC: Acero inoxidable

Acabado frontal: Anodizado

Acabado trasero: Conductor

De conformidad con: IEC 60297-3-101; IEEE 1101.1/10

Apantallamiento EMC: No (Retrofitable)

Altura (H): 128.4mm

Tipo de producto: Panel frontal

Anchura (W): 426.4mm

Por favor, ordene el material de fijación (mangas, tornillos de cuello) por separado.

Technical drawing of a rectangular metal plate. The main view shows a plate with overall width B and height H . The top edge has a width of 7.45 and a central slot with a width of 5.08 . The bottom edge has a width of 7.45 and a central slot with a width of 5.08 . The plate is shown with a thickness of 3 . Two detail views are provided: **X** shows a cross-section of the top edge with a radius of $R 1.1$ and a thickness of 1.8 . **Y** shows a cross-section of the bottom edge with a radius of $R 0.65$ and a thickness of 1.1 . The plate is shown with a thickness of 3 .

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE