


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

Power Utilities

NÚMERO DE CATÁLOGO

20848-617

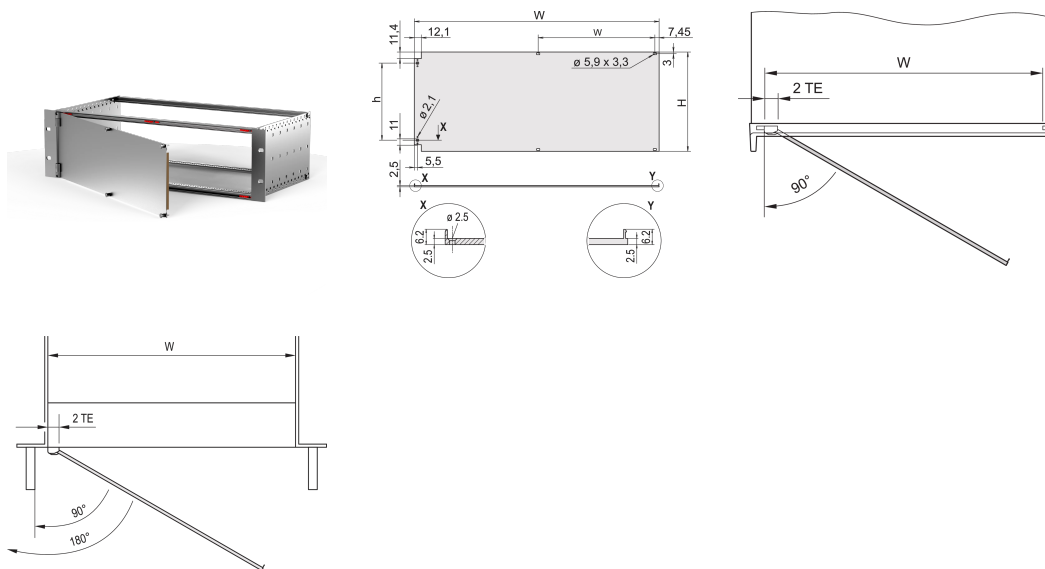

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICACIONES



CARACTERÍSTICAS

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for sub racks and cases

Hinges can be fitted on left or right

ATRIBUTOS DEL PRODUCTO

Tipo de producto: Panel frontal

Tipo: Panel frontal sin mango

Montaje: Con bisagras, lado

Apantallamiento EMC: No (Retrofitable)

Tipo de junta: Textile

Material: Aluminio

Acabado frontal: Anodizado

Acabado trasero: Conductivo

Bordes tratados: No

Altura del rack: 6 U

Altura: 261.8 mm

Ancho del rack: 84 HP

Anchura: 426.4 mm

Cantidad del paquete: 1

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE