


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Servicios públicos de energía

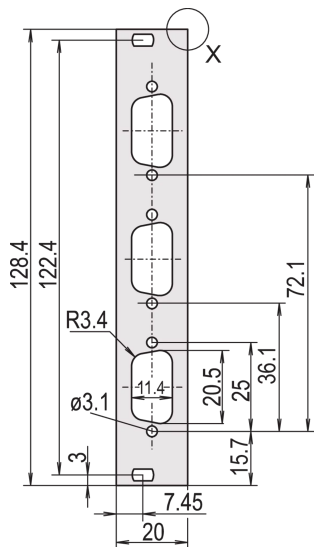

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICACIONES



CARACTERÍSTICAS

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

ESPECIFICACIONES

Table 1/3

Número de catálogo	Package Quantity	Montaje	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
--------------------	------------------	---------	-----------------	--------------	-------------	---------------

30118-348	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No
30118-349	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No
30118-350	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No
30118-351	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No
30118-352	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No
30118-353	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No
30118-354	5	Screw-on Front	Acero inoxidable	Anodizado	Conductive	No

Table 2/3						
Número de catálogo	Cumple con	EMC Shielding	Altura	Material	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U

Table 3/3			
Número de catálogo	Rack Width	Tipo	Ancho

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE