


Outdoor Unibody Cabinet

Servicios públicos de energía

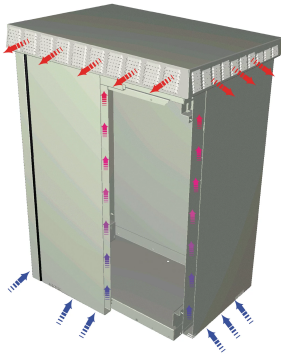

Telecom and Railway applications require sophisticated electronics in outdoor setups. nVent SCHROFF Outdoor cabinets shield such electronic components from extreme weather and vandalism, ensuring operational continuity.

CERTIFICACIONES



CARACTERÍSTICAS

Double-walled, Al

IP 55

One-piece inner case with removable outer cladding

Heat dissipation through natural convection, max. 5 W/K (11249-003) / 6 W/K (11249-005)

ESPECIFICACIONES

Table 1/2

Número de catálogo	Product Type	Product Family	Rack Height	Altura	Ancho	Profundidad
11249-003	Outdoor Cabinet	Unibody	16 U	930 mm	700 mm	500 mm
11249-005	Outdoor Cabinet	Unibody	20 U	1100 mm	700 mm	500 mm

Table 2/2

Número de catálogo	Wall Type	Door Type	Acceso	Refrigeración	EMC Shielding	Cumple con
11249-003	Double Walled	Single Door	Front	Natural Convection	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160
11249-005	Double Walled	Single Door	Front	Natural Convection	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160

ADDITIONAL PRODUCT DETAILS

Please order panel/slide mounts separately.

Further base/plinth heights on request.

Please order wall-mounting assembly kit separately.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE