


E650C-G Ground Sensor for Elexant 650c-Modbus

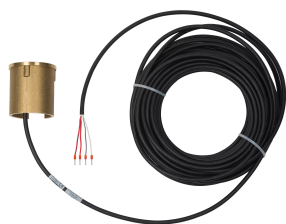

Ground sensor for combined measurement of temperature and moisture values in outdoor areas with foot or vehicle traffic. Robust version made of brass, fully encapsulated. Very low installation height, so particularly well suited to staircases, terraces, etc.

CARACTERÍSTICAS

Cable connection: To the side

Connection cable: 4 x 0.5 mm²

Temperature range for moisture measurement: -20°C to 30°C

ESPECIFICACIONES

Table 1/2

Número de catálogo	Nombre del artículo	Comunicaciones	Diámetro	Hazardous Area	Altura	Clasificación IP
1244-022796	E650C-G-HOUSING	No	68 mm	No	31 mm	IP68
1244-022794	E650C-G	No	68 mm	No	72 mm	IP68

Table 2/2

Número de catálogo	Nombre del artículo	Measuring Range
1244-022796	E650C-G-HOUSING	
1244-022794	E650C-G	-20 to 30 °C

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

Norteamérica

Tel +1.800.545.6258

Fax +1.800.527.5703

thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511

Fax +32.16.213.604

thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688

Fax +86.21.5426.3167

cn.thermal.info@nvent.com

Latinoamérica

Tel +1.713.868.4800

Fax +1.713.868.2333

thermal.info@nvent.com

Our powerful portfolio of brands:

RAYCHEM PYROTENAX TRACER NUHEAT