


# Front Panel, U-profile, Refrofit Shielding, 6 U, 84 HP

Servicios públicos de energía

## NÚMERO DE CATÁLOGO

**20848-189**

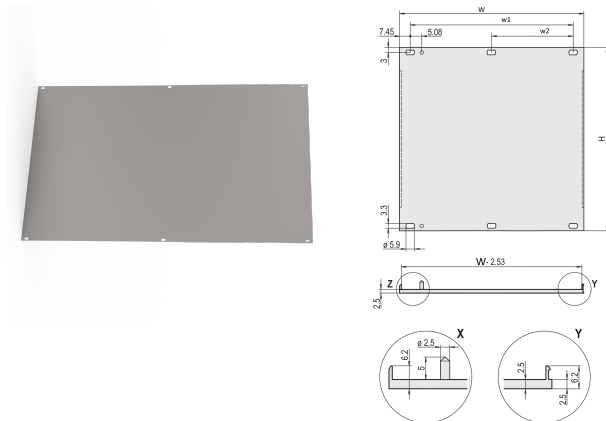

U-profile front panel for textile EMC gasket.

## CERTIFICACIONES



## CARACTERÍSTICAS

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

## ATRIBUTOS DEL PRODUCTO

Product Type: Front Panel

Type: Front Panel without Handle

Mounting: Screw-on Front

EMC Shielding: No (Retrofittable)

EMC Gasket Type: Textile

Material: Aluminio

Front Finish: Anodizado

Rear Finish: Conductive

Treated Edges: No

Rack Height: 6 U

Altura: 261,8 mm

Rack Width: 84 HP

Ancho: 426,4 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Please order fixing material (sleeves, collar screws) separately.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).

Differences in finish between 2 ... 12 HP and 14 ... 84 HP.

2 ... 12 HP: one-part U-profile

Please order textile EMC gasket separately.

Standard pack quantity: 2 to 28HP: 5 pieces, 42 to 84 HP: 1 piece, supplied in standard pack quantities (SPQ) only.

## ADVERTENCIA

---

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en [www.nvent.com](http://www.nvent.com) y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**