


HF Frame Type Plug-in Panel frontal, 3 U, 14HP, 2,5 mm, Al, Anodizado frontal, Conductivo trasero

NÚMERO DE CATÁLOGO

20838-004

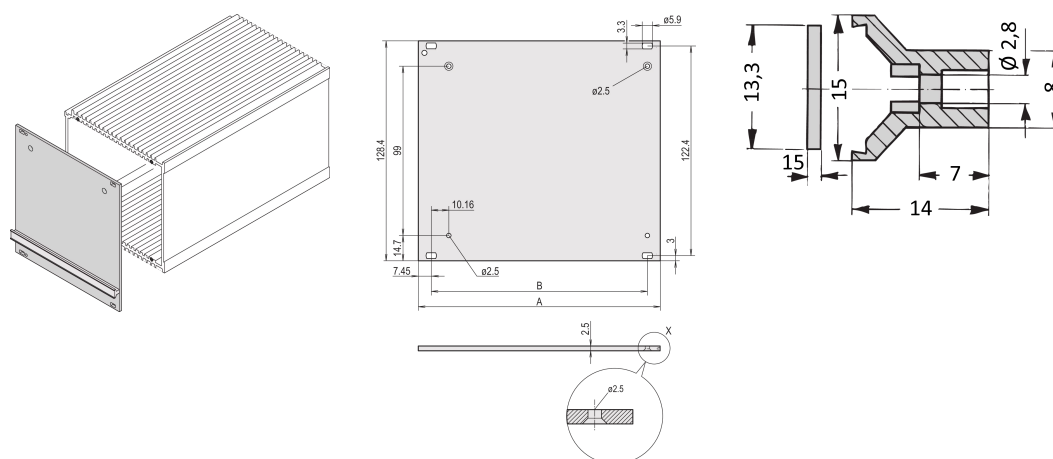

Al, 2,5 mm, anodizado frontal, conductor para cassette HF. Sin blindaje. Preparado para mango frontal de plástico.

CERTIFICACIONES



CARACTERÍSTICAS

Al, 2,5 mm, anodizado frontal, conductor; mango en forma de trapecio, gris, PPE, UL 94 V?1

Panel frontal con mango para atornillar en la unidad de enchufe HF

ATRIBUTOS DEL PRODUCTO

Ancho del rack: 14HP

Cantidad del paquete: 1

Tipo de accesorio: Panel frontal

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE