


# Mounting Plate for 19" Case and Subrack

## Servicios públicos de energía

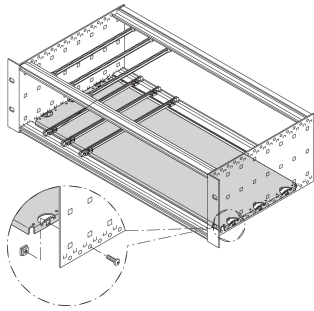

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

### CERTIFICACIONES



### CARACTERÍSTICAS

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

### ESPECIFICACIONES

Table 1/2

| Número de catálogo | Rack Width | Package Quantity | Profundidad | Material | Product Family                                | Product Type   |
|--------------------|------------|------------------|-------------|----------|-----------------------------------------------|----------------|
| 34562-752          | 84 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO | Mounting Plate |

| Número de catálogo | Rack Width | Package Quantity | Profundidad | Material | Product Family                                | Product Type   |
|--------------------|------------|------------------|-------------|----------|-----------------------------------------------|----------------|
| 34562-756          | 84 HP      | 1                | 232.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO            | Mounting Plate |
| 34562-760          | 84 HP      | 1                | 292.5 mm    | Aluminio | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-748          | 84 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-870          | 84 HP      | 1                | 352.5 mm    | Aluminio | EuropacPRO                                    | Mounting Plate |
| 34562-871          | 84 HP      | 1                | 412.5 mm    | Aluminio | EuropacPRO                                    | Mounting Plate |
| 34562-745          | 28 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO            | Mounting Plate |
| 34562-746          | 42 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-747          | 63 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-749          | 28 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO            | Mounting Plate |
| 34562-750          | 42 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO | Mounting Plate |
| 34562-751          | 63 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO | Mounting Plate |
| 34562-753          | 28 HP      | 1                | 232.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO            | Mounting Plate |
| 34562-754          | 42 HP      | 1                | 232.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO            | Mounting Plate |

| Número de catálogo | Rack Width | Package Quantity | Profundidad | Material | Product Family                     | Product Type   |
|--------------------|------------|------------------|-------------|----------|------------------------------------|----------------|
| 34562-755          | 63 HP      | 1                | 232.5 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-757          | 28 HP      | 1                | 292.2 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-758          | 42 HP      | 1                | 292.2 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |
| 34562-759          | 63 HP      | 1                | 292.2 mm    | Aluminio | EuropacPRO, RatiopacPRO, CompacPRO | Mounting Plate |

Table 2/2

| Número de catálogo | Ancho     | Works With | Certificaciones |
|--------------------|-----------|------------|-----------------|
| 34562-752          | 431.35 mm | Subracks   | RoHS            |
| 34562-756          | 431.35 mm | Subracks   | RoHS            |
| 34562-760          | 431.35 mm | Subracks   | RoHS            |
| 34562-748          | 324.67 mm | Subracks   | RoHS            |
| 34562-870          | 431.35 mm | Subracks   |                 |
| 34562-871          | 431.35 mm | Subracks   |                 |
| 34562-745          | 146.88 mm | Subracks   | RoHS            |
| 34562-746          | 217.99 mm | Subracks   | RoHS            |
| 34562-747          | 324.67 mm | Subracks   | RoHS            |
| 34562-749          | 146.88 mm | Subracks   | RoHS            |
| 34562-750          | 217.99 mm | Subracks   | RoHS            |
| 34562-751          | 324.67 mm | Subracks   | RoHS            |

| Número de catálogo | Ancho     | Works With | Certificaciones |
|--------------------|-----------|------------|-----------------|
| 34562-753          | 146.88 mm | Subracks   | RoHS            |
| 34562-754          | 217.99 mm | Subracks   | RoHS            |
| 34562-755          | 324.67 mm | Subracks   | RoHS            |
| 34562-757          | 146.88 mm | Subracks   | RoHS            |
| 34562-758          | 217.99 mm | Subracks   | RoHS            |
| 34562-759          | 324.67 mm | Subracks   | RoHS            |

### ADDITIONAL PRODUCT DETAILS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

### ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en [www.nvent.com](http://www.nvent.com) y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**