


U-profile Front Panel, Shieldable, D-Sub Cutouts

Servicios públicos de energía

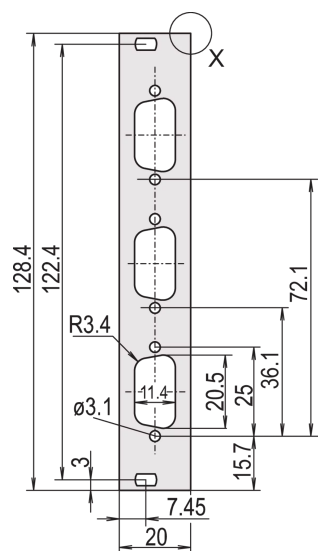

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICACIONES



CARACTERÍSTICAS

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

ESPECIFICACIONES

Table 1/3

Número de catálogo	Package Quantity	Montaje	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-749	5	Screw-on Front	Textile	Anodizado	Conductive	No

Número de catálogo	Package Quantity	Montaje	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-750	5	Screw-on Front	Textile	Anodizado	Conductive	No
30849-751	5	Screw-on Front	Textile	Anodizado	Conductive	No
30849-752	5	Screw-on Front	Textile	Anodizado	Conductive	No
30849-753	5	Screw-on Front	Textile	Anodizado	Conductive	No
30849-754	5	Screw-on Front	Textile	Anodizado	Conductive	No
30849-755	5	Screw-on Front	Textile	Anodizado	Conductive	No

Table 2/3

Número de catálogo	Cumple con	EMC Shielding	Altura	Material	Product Type	Rack Height
30849-749	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30849-750	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30849-751	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30849-752	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30849-753	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30849-754	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U
30849-755	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminio	Front Panel	3 U

Table 3/3

Número de catálogo	Rack Width	Tipo	Ancho
--------------------	------------	------	-------

30849-749	4 HP	Front Panel without Handle	20 mm
30849-750	4 HP	Front Panel without Handle	20 mm
30849-751	4 HP	Front Panel without Handle	20 mm
30849-752	4 HP	Front Panel without Handle	20 mm
30849-753	4 HP	Front Panel without Handle	20 mm
30849-754	4 HP	Front Panel without Handle	20 mm
30849-755	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE