


HF Frame Type Plug-in Panel frontal, 3 U, 12HP, 2,5 mm, AL, Anodizado frontal, Conductivo trasero

NÚMERO DE CATÁLOGO

20838-003

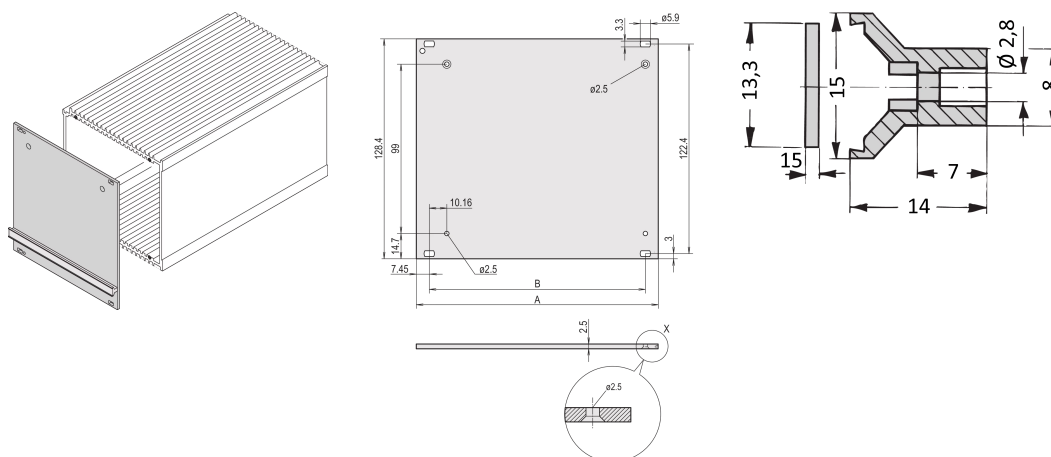

Al, 2,5 mm, anodizado frontal, conductor para cassette HF. Sin blindaje. Preparado para mango frontal de plástico.

CERTIFICACIONES



CARACTERÍSTICAS

Al, 2,5 mm, anodizado frontal, conductor; mango en forma de trapecio, gris, PPE, UL 94 V?1

Panel frontal con mango para atornillar en la unidad de enchufe HF

ATRIBUTOS DEL PRODUCTO

Ancho del rack: 12HP

Cantidad del paquete: 1

Tipo de accesorio: Panel frontal

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE