

# Horizontal Pouring Basin, Side Fill, 45°, Extended, Right Hand



Angular extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

## CARACTERÍSTICAS

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

## ESPECIFICACIONES

Table 1/2

| Número de catálogo | Material | Diámetro (Ø) | Longitud 1 (L1) | Longitud 2 (L2) | Anchura (W) | Altura 1 (H1) |
|--------------------|----------|--------------|-----------------|-----------------|-------------|---------------|
| WS2482RHD          | Grafito  | 54 mm        | 470 mm          | 97 mm           | 76 mm       | 203mm         |

Table 2/2

| Número de catálogo | Altura 2 (H2) | Ángulo (a) |
|--------------------|---------------|------------|
| WS2482RHD          | 89mm          | 45 °       |


## DETALLES ADICIONALES DEL PRODUCTO

RBWS2482 pouring basins require one RBW350 and one RBW664 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMAS

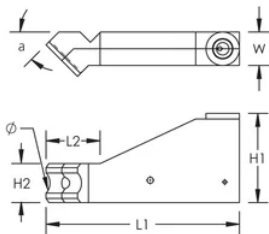

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

Norteamérica

+1.800.753.9221  
Opción 1: Atención al cliente  
Opción 2: Soporte técnico

Europa

Países Bajos:  
+31 800-0200135  
Francia:  
+33 800 901 793

Europa

Alemania:  
800 1890272  
Otros países:  
+31 13 5835404

Asia-Pacífico

Shanghái:  
+86 21 2412 1618/19  
Sídney:  
+61 2 9751 8500



Nuestro gran portafolio de marcas:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE