


# EuropacPRO Mounting Plate for Use With Cover Plate

## Servicios públicos de energía

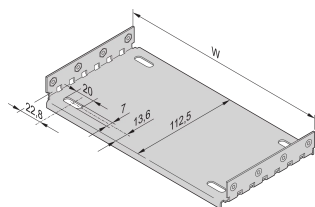

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

## CERTIFICACIONES



## CARACTERÍSTICAS

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

## ESPECIFICACIONES

Table 1/2

| Número de catálogo | Rack Width | Package Quantity | Profundidad | Material | Product Family | Product Type   |
|--------------------|------------|------------------|-------------|----------|----------------|----------------|
| 34563-019          | 63 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |

| Número de catálogo | Rack Width | Package Quantity | Profundidad | Material | Product Family | Product Type   |
|--------------------|------------|------------------|-------------|----------|----------------|----------------|
| 34563-001          | 28 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-003          | 63 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-044          | 84 HP      | 1                | 412.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-042          | 84 HP      | 1                | 352.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-009          | 28 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-002          | 42 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-028          | 84 HP      | 1                | 292.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-026          | 84 HP      | 1                | 232.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-014          | 42 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-024          | 84 HP      | 1                | 172.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |
| 34563-004          | 84 HP      | 1                | 112.5 mm    | Aluminio | EuropacPRO     | Mounting Plate |

| Table 2/2          |           |            |                 |
|--------------------|-----------|------------|-----------------|
| Número de catálogo | Ancho     | Works With | Certificaciones |
| 34563-019          | 324.67 mm | Subracks   | RoHS            |
| 34563-001          | 146.88 mm | Subracks   | RoHS            |
| 34563-003          | 324.67 mm | Subracks   | RoHS            |
| 34563-044          | 431.35 mm | Subracks   |                 |
| 34563-042          | 431.35 mm | Subracks   |                 |
| 34563-009          | 146.88 mm | Subracks   | RoHS            |

| Número de catálogo | Ancho     | Works With | Certificaciones |
|--------------------|-----------|------------|-----------------|
| 34563-002          | 217.99 mm | Subracks   | RoHS            |
| 34563-028          | 431.35 mm | Subracks   |                 |
| 34563-026          | 431.35 mm | Subracks   |                 |
| 34563-014          | 217.99 mm | Subracks   | RoHS            |
| 34563-024          | 431.35 mm | Subracks   | RoHS            |
| 34563-004          | 431.35 mm | Subracks   | RoHS            |

### ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en [www.nvent.com](http://www.nvent.com) y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE