


Panel frontal de la unidad enchufable tipo marco HF, blindaje refrofit con junta de acero, 3 U, 10 HP

NÚMERO DE CATÁLOGO

20838-094

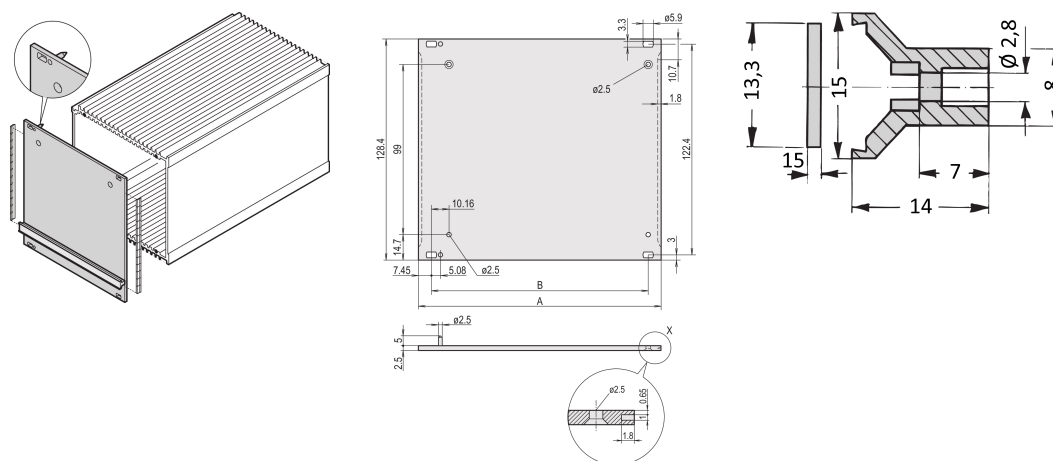

Al, 2,5 mm, anodizado delantero, conductor trasero, con ranuras laterales para empaque de acero inoxidable EMC. (Solicite por separado), pasador de alineación presionado; mango en forma de trapecio, gris, PPE, UL 94 V?1.

CERTIFICACIONES



CARACTERÍSTICAS

Al, 2,5 mm, anodizado delantero, conductor trasero, con ranuras laterales para junta de acero inoxidable EMC (pedir por separado), pasador de alineación presado; mango en forma de trapecio, gris, PPE, UL 94 V?1

Panel frontal con mango para atornillar en la unidad de enchufe HF

ATRIBUTOS DEL PRODUCTO

Ancho del rack: 10HP

Cantidad del paquete: 1

Material: Aluminio

Altura del rack: 3U

Net Weight: 0.05kg

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE