

T-Series Horizontal Filler Material Kit



T-Series horizontal filler material kits contain the following: Filler material, two horizontal packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

CARACTERÍSTICAS

Simplifies ordering

Used to splice the same diameter bars

All components are for one-time use

ESPECIFICACIONES

Table 1/1

Número de catálogo	Tamaño de las barras de armado, métrico	Tamaño de las barras de armado, EE. UU.	Tamaño de armadura, Canadá
RBT121018HB	38 mm	#12	
RBT5101HB	16 mm	#5	15M
RBT6101HB	20 mm	#6	20M
RBT7101HB	22 mm	#7	
RBT8101HB	25 mm	#8	25M
RBT81011HB	25 mm	#8	25M
RBT9101HB	28 mm	#9	30M

Número de catálogo	Tamaño de las barras de armado, métrico	Tamaño de las barras de armado, EE. UU.	Tamaño de armadura, Canadá
RBT91011HB	28 mm	#9	30M
RBT1091HB	32 mm	#10	
RBT11101HB	36 mm	#11	35 MILLONES
RBT14101HB	43 mm	#14	45 MILLONES
RBT1891HB	57 mm	#18	55 MILLONES

DETALLES ADICIONALES DEL PRODUCTO


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT5101HB	RBF40	RBS354710	RBS5037	RBS5038
RBT6101HB	RBF50	RBS35477	RBS5037	RBS5038
RBT7101HB	RBF50	RBS35478	RBS5037	RBS5038
RBT81011HB	RBF70	RBS354710	RBS5037	RBS5038
RBT8101HB	RBF55	RBS354710	RBS5037	RBS5038
RBT91011HB	RBF90	RBS354711	RBS5037	RBS5038
RBT9101HB	RBF80	RBS354711	RBS5037	RBS5038
RBT1091HB	RBF90	RBS354712	RBS5037	RBS5038
RBT11101HB	RBF105	RBS354712	RBS5037	RBS5038
RBT121018HB	RBF180	RBS354715	RBS5037	RBS5038
RBT14101HB	RBF195	RBS354715	RBS5037	RBS5039
RBT1891HB	RBF270	RBS354720	RBS5037	RBS5039

DIAGRAMAS

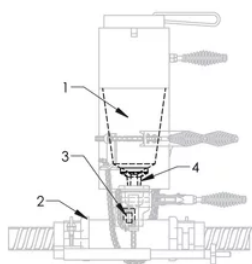

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

Norteamérica

+1.800.753.9221

Opción 1: Atención al cliente

Opción 2: Soporte técnico

Europa

Países Bajos:

+31 800-0200135

Francia:

+33 800 901 793

Europa

Alemania:

800 1890272

Otros países:

+31 13 5835404

Asia-Pacífico

Shanghái:

+86 21 2412 1618/19

Sídney:

+61 2 9751 8500



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

©2025 nVent. Todas las marcas y logotipos de nVent son propiedad de nVent Services GmbH o sus filiales, o se utilizan bajo su licencia. El resto de las marcas comerciales son propiedad de sus respectivos propietarios. nVent se reserva el derecho a cambiar las especificaciones sin previo aviso.

Este documento lo ha generado el sistema.