

T-Series Horizontal Fixed Angle Splice Kit, Top Fill, 45-75°



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

CARACTERÍSTICAS

Simplifies ordering

Used to splice the same diameter bars

ESPECIFICACIONES

Manguito: Longitud estándar

Table 1/2

Número de catálogo	Ángulo (a)	Tamaño de las barras de armado, métrico	Tamaño de las barras de armado, EE. UU.	Tamaño de armadura, Canadá	Longitud 1 (L1)	Longitud 2 (L2)
RBT189175H	75 °	57 mm	#18	55 MILLONES	129 mm	390 mm
RBT189145H	45 °	57 mm	#18	55 MILLONES	180 mm	268 mm

Table 2/2

Número de catálogo	Altura 1 (H1)	Altura 2 (H2)	Diámetro (Ø)
RBT189175H	576mm	253mm	178 mm

Número de catálogo	Altura 1 (H1)	Altura 2 (H2)	Diámetro (Ø)
RBT189145H	601mm	225mm	178 mm

DETALLES ADICIONALES DEL PRODUCTO


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

Splice Kit Components							
Splice Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube	Sleeve	Pouring Basin	Pouring Basin Crucible
RBT189145H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891HA	RBWS1537M	RBWS22777
RBT189175H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891A	RBWS2224M	RBWS22777

DIAGRAMAS

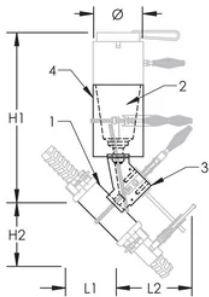

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

Norteamérica

+1.800.753.9221

Opción 1: Atención al
cliente

Opción 2: Soporte técnico

Europa

Países Bajos:

+31 800-0200135

Francia:

+33 800 901 793

Europa

Alemania:

800 1890272

Otros países:

+31 13 5835404

Asia-Pacífico

Shanghái:

+86 21 2412 1618/19

Sídney:

+61 2 9751 8500



Nuestro gran portafolio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

©2025 nVent. Todas las marcas y logotipos de nVent son propiedad de nVent Services GmbH o sus filiales, o se utilizan bajo su licencia. El resto de las marcas comerciales son propiedad de sus respectivos propietarios. nVent se reserva el derecho a cambiar las especificaciones sin previo aviso.

Este documento lo ha generado el sistema.