


# Air Terminal Base, Stamped Adjustable, Imperial Thread

## Power Utilities

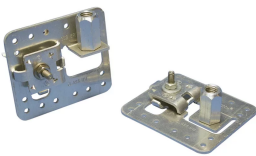

### CARACTERÍSTICAS

For use on flat, vertical or sloping surfaces

Air terminal support tab is field adjustable, eliminating the need for swivel adaptors

Available pre-configured for vertical applications

Install with adhesive or screw down fixings

Positive single bolt tension for multi-directional cable clamping

### ESPECIFICACIONES


Table 1/1

| Número de catálogo | Tamaño del conductor, UL     | Altura (H) | Anchura (W) |
|--------------------|------------------------------|------------|-------------|
| LPA30212           | Clase 1 - Clase 2 (4/0 máx.) | 34.92 mm   | 101.600 mm  |

### DETALLES ADICIONALES DEL PRODUCTO

Vertical type bases are factory pre-configured for vertical mount applications.

## DIAGRAMAS

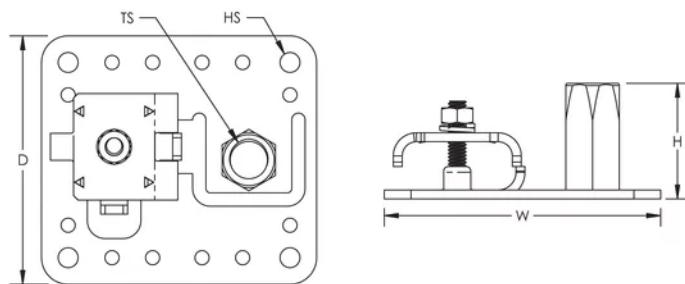

## ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Nuestro gran portafolio de marcas:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**