


# Front Panel 2 HP Wide for Combined Mounting

## Servicios públicos de energía

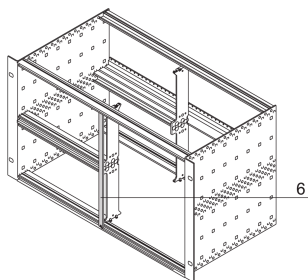

The 2 HP wide front panel covers an open slot. The non-shielded version can be fixed with screws and washers. Due to the 2 HP width, no sleeves can be used.

### CERTIFICACIONES



### CARACTERÍSTICAS

Flat front panel 6 U, 2 HP, Al, 2.5 mm

### ESPECIFICACIONES

| Table 1/1          |              |             |               |             |                  |
|--------------------|--------------|-------------|---------------|-------------|------------------|
| Número de catálogo | Front Finish | Rear Finish | Treated Edges | Rack Height | Package Quantity |
| 30847-472          | Anodizado    | Conductive  | No            | 6 U         | 5                |

### ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVERTENCIA

---

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en [www.nvent.com](http://www.nvent.com) y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**