


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Power Utilities

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

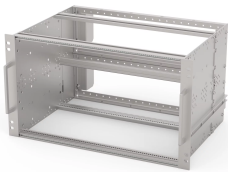

CERTIFICACIONES



CARACTERÍSTICAS

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

ESPECIFICACIONES

Table 1/3

Número de catálogo	Altura del rack	Ancho del rack	Fondo	Cantidad del paquete	Para montaje	Profundidad de la placa
21500-070	6 U	36 HP	320 mm	1	Plano trasero	220 mm
21500-067	3 U	36 HP	320 mm	1	Plano trasero	220 mm
21500-029	3 U	84 HP	320 mm	1	Plano trasero	220 mm
21500-027	6 U	84 HP	320 mm	1	Plano trasero	220 mm

Table 2/3

Número de catálogo	Tipo de junta EMC	Tolerancia a impactos y vibraciones	Mango incluido	Montaje	De conformidad con	Apantallamiento EMC
21500-070	Textil	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No
21500-067	Textil	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No
21500-029	Textil	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No
21500-027	Textil	5 g (force)	Sí	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No

Table 3/3

Número de catálogo	Tipo de producto	Carga estática	Certificaciones
21500-070	Subrack/chasis	15 kgf	RoHS
21500-067	Subrack/chasis	15 kgf	RoHS
21500-029	Subrack/chasis	15 kgf	RoHS, SNCF

Número de catálogo	Tipo de producto	Carga estática	Certificaciones
21500-027	Subrack/chasis	15 kgf	RoHS, SNCF

DETALLES ADICIONALES DEL PRODUCTO

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Nuestro gran portafolio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE