

# Speedway Cable Ladder Flat Elbow, 90°



## CERTIFICATIONS



## FEATURES

- Creates a 90° corner change in cable tray direction
- Provides optimal support for high-performance low voltage and data cables
- Innovative SPEEDLOK integrated coupling system
- Safety edge protects cables during installation
- Slotted side channel, eliminating field drilling for cut-to-length applications
- IEC 61537 load rating and earthing compliant
- Responsive design and layout services, including seismic

## SPECIFICATIONS


- Finish:** Hot-Dip Galvanized
- Material:** Steel

Table 1/1

Catalog Number	Article Number	Width (W)	Angle (a)	A	B	C

CL110X900FE9 OHD	840250	900 mm	90 °	1295 mm	1295 mm	80 mm
CL110X600FE9 OHD	840230	600 mm	90 °	995 mm	995 mm	80 mm
CL110X750FE9 OHD	840240	750 mm	90 °	1145 mm	1145 mm	80 mm
CL110X450FE9 OHD	840220	450 mm	90 °	845 mm	845 mm	80 mm
CL110X150FE9 OHD	840200	150 mm	90 °	545 mm	545 mm	80 mm
CL110X300FE9 OHD	840210	300 mm	90 °	695 mm	695 mm	80 mm

## DIAGRAMS

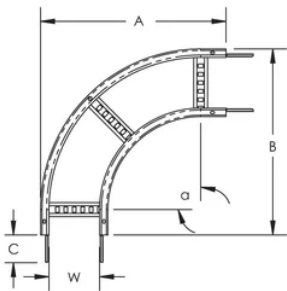

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

