

PEMSA Wire Basket Tray C Bracket

Data Solutions



CERTIFICATIONS



FEATURES

Easy to use, quick connect feature

Ideal for ceiling, wall and channel installations

Side load access for cable installation

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Table 1/1

Catalog Number	Article Number	Length 1 (L1)	Length 2 (L2)	Width (W)	Height (H)	Static Load
WBT200CBRKT	820330	137mm	265mm	54mm	190mm	284N

CatalogNumber	Article Number	Length 1 (L1)	Length 2 (L2)	Width (W)	Height (H)	Static Load
WBT100CBRKT	820310	137mm	165mm	54mm	190mm	327N
WBT300CBRKT	820340	137mm	365mm	54mm	190mm	245N
WBT400CBRKT	820350	137mm	465mm	54mm	190mm	177N
WBT150CBRKT	820320	137mm	200mm	54mm	190mm	353N

DIAGRAMS

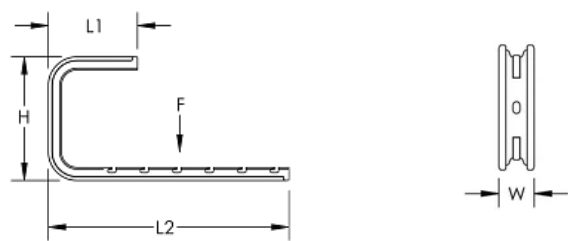

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE