


Alumiiniset riviliitinkotelot, HALP

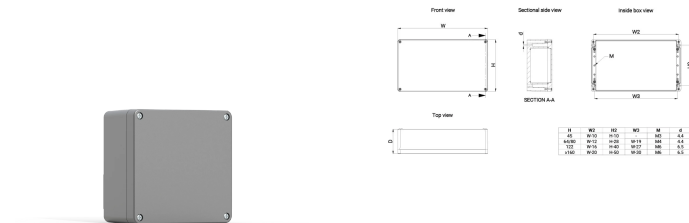

The aluminium terminal box range, HALP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The HALP range is well suited for indoor and outdoor environments thanks to excellent corrosion resistance. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

INDUSTRY STANDARDS

CE UKCA

EAC

GOST

IP

FEATURES

Material: Aluminium alloy EN AC-47100.

Gasket: Standard supply fitted with a polyurethane gasket. Silicone, neoprene and EPDM gaskets are available on request.

Temperature resistance: -30 °C to +80 °C.

Protection: IP 66, 67, IK 09, 08 for HALP050503GE.

Finish: RAL 7001.

Approvals: CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery: Body and cover are manufactured from aluminum, cover screws are made of stainless steel.

SPECIFICATIONS

Material:	Aluminum
Finish:	Powder Coated
Color Code:	RAL 7001
Color:	Silver Grey

Table 1/1

Catalog Number	Height (H)	Width (W)	Depth (D)	Body Thickness	Cover Thickness	Cover Screw Quantity
HALP050503GE	45mm	50mm	30mm	3mm	2mm	2
HALP080806GE	80mm	74mm	57mm	3.5mm	2.5mm	4
HALP081306GE	80mm	124mm	57mm	3.5mm	2.6mm	4
HALP081806GE	80mm	175mm	57mm	3.5mm	2.5mm	4
HALP082506GE	80mm	249mm	57mm	3.5mm	2.5mm	4
HALP060604GE	64mm	57mm	36mm	3.5mm	3mm	4
HALP061004GE	64mm	98mm	36mm	3.5mm	3mm	4
HALP061504GE	64mm	150mm	36mm	3.5mm	3mm	4
HALP121208GE	122mm	121mm	80mm	4.1mm	3.7mm	4
HALP123608GE	122mm	359mm	80mm	4.1mm	3.7mm	4
HALP161609GE	160mm	160mm	90mm	4.1mm	3.7mm	4
HALP163609GE	160mm	359mm	90mm	4.1mm	3.7mm	4
HALP233311GE	230mm	329mm	110mm	4.1mm	3.7mm	4
HALP233318GE	230mm	329mm	180mm	4.5mm	3.7mm	4
HALP234011GE	230mm	400mm	110mm	4.1mm	3.7mm	4
HALP121209GE	122mm	121mm	90mm	4.1mm	4mm	4

Catalog Number	Height (H)	Width (W)	Depth (D)	Body Thickness	Cover Thickness	Cover Screw Quantity
HALP122208GE	122mm	219mm	80mm	4mm	4mm	4
HALP122209GE	122mm	219mm	90mm	4mm	4mm	4
HALP162609GE	160mm	260mm	90mm	4mm	4mm	4
HALP165609GE	160mm	560mm	90mm	4mm	4mm	6
HALP232011GE	230mm	199mm	110mm	4.1mm	4.1mm	4
HALP236011GE	230mm	599mm	110mm	4mm	4mm	6

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE