


# EuropacPRO Cover Plate for Bolting to Rugged Side Panel

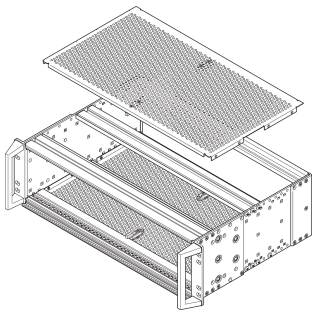

A cover plate is used for electromagnetic shielding or as mechanical protection.

## CERTIFICATIONS



## FEATURES

Perforation degree 58%

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 84HP        |
| <b>Material:</b>       | Aluminum    |
| <b>Product Type:</b>   | Cover Plate |
| <b>Product Family:</b> | EuropacPRO  |
| <b>Finish:</b>         | Passivated  |
| <b>Type:</b>           | Perforated  |
| <b>Works With:</b>     | Subracks    |

Table 1/1

| Catalog Number | Depth | Package Quantity | Package Unit | Torque | Quick Ship |
|----------------|-------|------------------|--------------|--------|------------|
| 24568-004      | 175mm | 2                | Pair         | 2.1N·m | No         |

| Catalog Number | Depth    | Package Quantity | Package Unit | Torque | Quick Ship |
|----------------|----------|------------------|--------------|--------|------------|
| 24568-036      | 277.75mm | 2                | Pair         | 2.1N·m | No         |
| 24568-032      | 275mm    | 2                | Pair         | 2.1N·m | No         |
| 24568-020      | 355mm    | 2                | Pair         | 2.1N·m | No         |
| 24568-016      | 295mm    | 2                | Pair         | 2.1N·m | No         |
| 24568-012      | 295mm    | 2                | Pair         | 2.1N·m | No         |
| 24568-008      | 235mm    | 2                | Pair         | 2.1N·m | No         |

## ADDITIONAL PRODUCT DETAILS

A top cover locking mechanism is optionally available that also fixes the top cover in the front and rear guide rail.

4 stainless steel EMC contact strips per subrack are required for shielding, please order separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**