


# Novastar 19" Shelf, Stationary

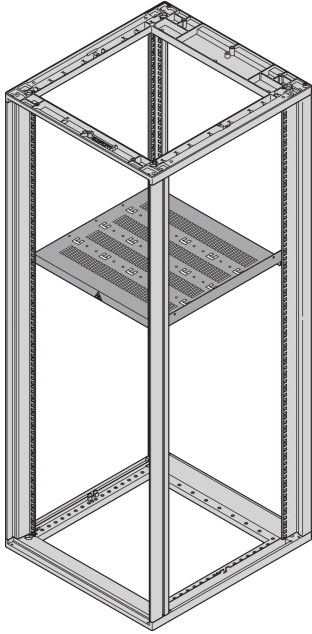

Novastar 19" Shelf, Stationary with 75 Kg load capacity, perforated for ease of assembly.

## CERTIFICATIONS

---



## FEATURES

---

Mounting height 1 U, for fitting on the vertical cabinet uprights

Static load-carrying capacity 75 kg

Perforated for assembling cable ties

St, 1.5 mm

With perforation

Color RAL 7021

## SPECIFICATIONS

---

**Product Type:** Shelf

**Material:** Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Color	Color Code	Finish
27230-051	553mm	500mm	1	Black Grey	RAL 7021	Powder Coated
27230-165	740mm	900mm	1	Black Grey	RAL 7021	Powder Coated
27230-089	553mm	1000mm	1	Black Grey	RAL 7021	Powder Coated
27230-053	553mm	800mm	1	Black Grey	RAL 7021	Powder Coated
27230-088	553mm	900mm	1	Black Grey	RAL 7021	Powder Coated
27230-052	553mm	600mm	1	Black Grey	RAL 7021	Powder Coated

Table 2/2

Catalog Number	Height	Type	Quick Ship
27230-051	44.45mm	Stationary Shelf	No
27230-165	44.45mm	Stationary Shelf	No
27230-089	44.45mm	Stationary Shelf	No
27230-053	44.45mm	Stationary Shelf	No
27230-088	44.45mm	Stationary Shelf	No
27230-052	44.45mm	Stationary Shelf	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**