


Varistar CP Seismic Base Plate, EMC, with Cable Entry, One-Piece

Varistar CP Base Plate for Rear Cable Ducting, plain for IP 55 or EMC applications.

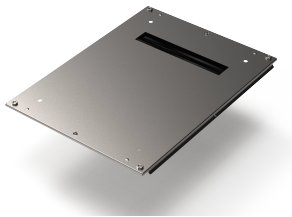

FEATURES

Installation from outside

Cutout at rear

60 mm deep

Cable ducting with IP 55 / EMC gasket

SPECIFICATIONS

Product Type: Cabinet/Rack Base

Finish: Hot-Dip Galvanized

Material: Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Complies With	Type	Works With
20630-317	600mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP
20630-324	800mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP
20630-323	1000mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP

CatalogNumber	Width	Depth	Package Quantity	Complies With	Type	Works With
20630-322	800mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP
20630-321	600mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP
20630-320	600mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP
20630-319	600mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP
20630-318	600mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Cable Entry	Varistar CP

Table 2/2

Catalog Number	Quick Ship
20630-317	No
20630-324	No
20630-323	No
20630-322	No
20630-321	No
20630-320	No
20630-319	No
20630-318	No

ADDITIONAL PRODUCT DETAILS

Varistar CP Base Plate for Rear Cable Ducting, plain for IP 55 or EMC applications.

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE