

# Horizontal Pouring Basin, Side Fill, 45°, Right Hand



Angular side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

## FONCTIONS

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

## SPÉCIFICATIONS

**Matériau:** Graphite

Table 1/2

Référence catalogue	Diamètre (Ø)	Longueur 1 (L1)	Longueur 2 (L2)	Largeur (W)	Hauteur 1 (H1)	Hauteur 2 (H2)
RBWS2620RHF	64 mm	141 mm	83 mm	76 mm	154mm	76mm
RBWS2620RHM	95 mm	141 mm	83 mm	76 mm	154mm	76mm
RBWS2620RHJ	76 mm	141 mm	83 mm	76 mm	154mm	76mm

Table 2/2

Référence catalogue	Angle (a)
RBWS2620RHF	45 °

Référence catalogue	Angle (a)
RBWS2620RHM	45 °
RBWS2620RHJ	45 °


## INFORMATIONS PRODUIT COMPLÉMENTAIRES

RBWS2620 pouring basins require one RBW350 and one RBW664 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMMES

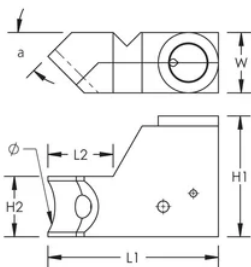

## AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur [www.nvent.com](http://www.nvent.com) et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Notre gamme complète de marques:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**