

Horizontal Pouring Basin, Side Fill, Extended



Extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

FONCTIONS

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

SPÉCIFICATIONS

Matériau: Graphite

Table 1/1

Référence catalogue	Diamètre (Ø)	Longueur 1 (L1)	Longueur 2 (L2)	Largeur (W)	Hauteur 1 (H1)	Hauteur 2 (H2)
RBHSA9750X	38 mm	248 mm	38 mm	76 mm	127mm	76mm
RBHSB10560X	38 mm	267 mm	38 mm	76 mm	152mm	76mm
RBHSB12065X	38 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSA9050D	54 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9050F	64 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9560M	95 mm	241 mm	38 mm	76 mm	152mm	76mm


Référence catalogue	Diamètre (Ø)	Longueur 1(L1)	Longueur 2(L2)	Largeur (W)	Hauteur 1 (H1)	Hauteur 2 (H2)
RBHSB12065C	48 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065J	76 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065M	95 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14065J	76 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14070D	54 mm	356 mm	38 mm	76 mm	178mm	76mm
RBHSB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBHSB16070F	64 mm	406 mm	38 mm	76 mm	178mm	76mm
RBHSB17070C	48 mm	432 mm	38 mm	76 mm	178mm	76mm
RBHSB177550 M	95 mm	451 mm	38 mm	76 mm	127mm	76mm
RBHSC23010M	95 mm	584 mm	38 mm	76 mm	254mm	76mm
RBHSC23075M	95 mm	584 mm	38 mm	76 mm	191mm	76mm
RBHSC30070D	54 mm	762 mm	38 mm	76 mm	191mm	76mm

INFORMATIONS PRODUIT COMPLÉMENTAIRES

RBHSA pouring basins require one RBW332 pouring basin frame and two RBS5000 bolt retainers. RBHSB pouring basins require one RBW3321 pouring basin frame and one RBS5000 bolt retainer. RBHSC pouring basins require one RBW3322 pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

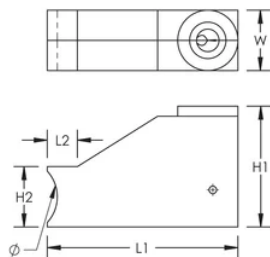

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE