

T-Series Horizontal Fixed Angle Splice Kit, Top Fill, 45-75°



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

FONCTIONS

Simplifies ordering

Used to splice the same diameter bars

SPÉCIFICATIONS

Manchon: Longueurs standard

Table 1/2

Référence catalogue	Angle (a)	Taille de barre d'armature, métrique	Taille de barre d'armature, US	Taille de barre d'armature, Canada	Longueur 1 (L1)	Longueur 2 (L2)
RBT189175H	75 °	57 mm	#18	55M	129 mm	390 mm
RBT189145H	45 °	57 mm	#18	55M	180 mm	268 mm

Table 2/2

Référence catalogue	Hauteur 1 (H1)	Hauteur 2 (H2)	Diamètre (Ø)
RBT189175H	576mm	253mm	178 mm
RBT189145H	601mm	225mm	178 mm

INFORMATIONS PRODUIT COMPLÉMENTAIRES


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

Splice Kit Components							
Splice Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube	Sleeve	Pouring Basin	Pouring Basin Crucible
RBT189145H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891HA	RBWS1537M	RBWS22777
RBT189175H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891A	RBWS2224M	RBWS22777

DIAGRAMMES

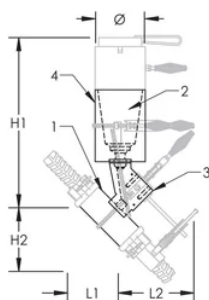

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Notre gamme complète de marques:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE