

Air Terminal Base, Horizontal Mount, Imperial Thread

Power Utilities



FONCTIONS


Can be fastened mechanically or bonded using hot pitch, roofing compound or commercial adhesive on built-up roof surfaces or other location where holes cannot be made

Positive single bolt tension for multi-directional cable clamping

SPÉCIFICATIONS

Table 1/1

Référence catalogue	Taille de conducteur, UL	Hauteur (H)	Largeur (W)	Poids unitaire
LPA30912	Classe 1 - Classe 2 (4/0 max.)	20.64 mm	101.600 mm	0.141 kg

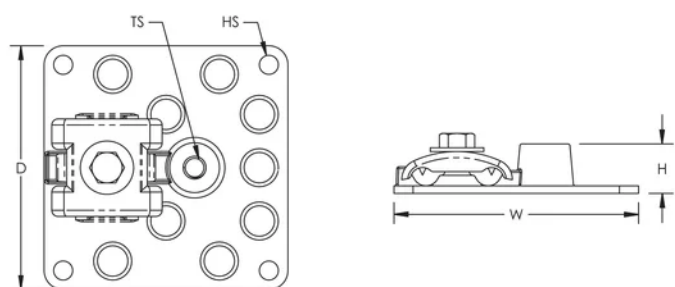

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.



Notre gamme complète de marques:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE