


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Centrale d'électricité

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

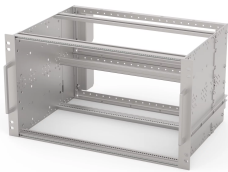

CERTIFICATIONS



CARACTÉRISTIQUES

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

LES CARACTÉRISTIQUES TECHNIQUES

Table 1/3

Référence catalogue	Rack Height	Rack Width	Profondeur	Package Quantity	For Mounting	Board Depth
21500-070	6 U	36 HP	320 mm	1	Carte fond de panier	220 mm
21500-067	3 U	36 HP	320 mm	1	Carte fond de panier	220 mm
21500-029	3 U	84 HP	320 mm	1	Carte fond de panier	220 mm
21500-027	6 U	84 HP	320 mm	1	Carte fond de panier	220 mm

Table 2/3

Référence catalogue	EMC Gasket Type	Shock and Vibration Tolerance	Handle Included	Montage	Conformité à	EMC Shielding
21500-070	Textile	5 g (force)	Oui	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Non
21500-067	Textile	5 g (force)	Oui	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Non
21500-029	Textile	5 g (force)	Oui	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Non
21500-027	Textile	5 g (force)	Oui	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Non

Table 3/3

Référence catalogue	Product Type	Charge statique	Certifications
21500-070	Subrack/Chassis	15 kgf	RoHS
21500-067	Subrack/Chassis	15 kgf	RoHS
21500-029	Subrack/Chassis	15 kgf	RoHS, SNCF

Référence catalogue	Product Type	Charge statique	Certifications
21500-027	Subrack/Chassis	15 kgf	RoHS, SNCF

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE