

T-Series Vertical Installation Equipment



T-Series vertical installation equipment kits contain the following: Pouring basin frame, crucible frame set (crucible chain assembly, crucible extension, crucible cover), two end alignment fittings and a bottom support clamp. Installation equipment kits contain components that are long lasting and often interchangeable with other sizes. Ordering installation equipment kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

FONCTIONS

Simplifies ordering

Used to splice the same diameter bars

All components are designed for an extended life

SPÉCIFICATIONS

Table 1/1

Référence catalogue	Matériau	Taille de barre d'armature, métrique	Taille de barre d'armature, US	Taille de barre d'armature, Canada
RBW7395V	Acier, Graphite	16 mm	#5	15M
RBW7396V	Acier, Graphite	20 mm	#6	20M
RBW7397V	Acier, Graphite	22 mm	#7	
RBW7398V	Acier, Graphite	25 mm	#8	25M
RBW7399V	Acier, Graphite	28 mm	#9	30M
RBW73910V	Acier, Graphite	32 mm	#10	
RBW73911V	Acier, Graphite	36 mm	#11	35M


Référence catalogue	Matériau	Taille de barre d'armature, métrique	Taille de barre d'armature, US	Taille de barre d'armature, Canada
RBW73914V	Acier, Graphite	43 mm	#14	45M
RBW73918V	Acier, Graphite	57 mm	#18	55M

INFORMATIONS PRODUIT COMPLÉMENTAIRES

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Components can also be purchased separately: (1) Pouring Basin Frame, (2) Crucible Chain Assembly, (3) Crucible Extension, (4) Crucible Cover, (5) End Alignment Fitting, and (6) Bottom Support Clamp.

DIAGRAMMES

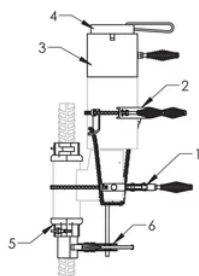

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés uniquement comme indiqué dans les feuilles d'instructions et les documents de formation de nVent. Les feuilles d'instructions sont disponibles sur www.nvent.com et auprès de votre représentant du service client nVent. Une installation incorrecte, une mauvaise utilisation, une mauvaise application ou tout autre défaut de respect total des instructions et des avertissements de nVent peut entraîner une défaillance du produit, des dommages matériels, des blessures corporelles graves et la mort et/ou annuler votre garantie.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Notre gamme complète de marques:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE