


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Centrale d'électricité

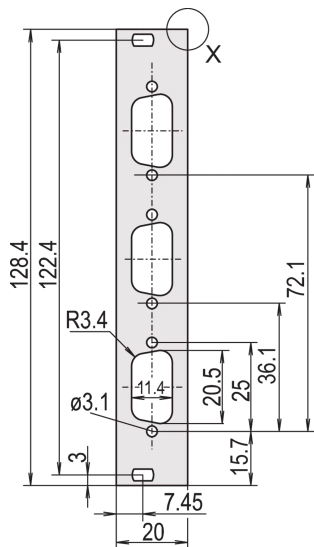

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICATIONS



CARACTÉRISTIQUES

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

LES CARACTÉRISTIQUES TECHNIQUES

Table 1/3

Référence catalogue	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
---------------------	------------------	---------	-----------------	--------------	-------------	---------------

30118-348	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non
30118-349	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non
30118-350	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non
30118-351	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non
30118-352	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non
30118-353	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non
30118-354	5	Screw-on Front	Acier inoxydable	Anodisé	Conductive	Non

Table 2/3						
Référence catalogue	Conformité à	EMC Shielding	Hauteur	Matériau	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Panneau avant	3 U

Table 3/3			
Référence catalogue	Rack Width	Type	Largeur

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte, une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE