


MultipacPRO 19" Chassis, Steel, AlZn, Plain Top and Base

Centrale d'électricité

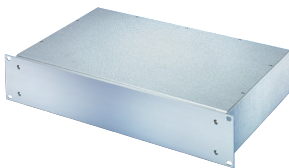

This 19" chassis is a form of subrack which accepts horizontal board mounting or the mounting of non-standard components like transformers or other heavy load accessories typically mounted on a chassis plate. This version is produced from sheet metal, Al-Zn coated and have plain top and bottom covers.

CERTIFICATIONS



CARACTÉRISTIQUES

Steel (AlZn coated) with Al extrusion front panel

Detachable front and rear panel for easy machining

IP 20, in accordance with IEC 60529

Supplied as space-saving flat-pack

EMC shielding: Approx. 20dB(A) at 2GHz without shielding material. >40dB(A) at 1Ghz with addition of stainless steel gasket between front panel and case body

Internal and external dimensions in accordance with: IEC 60297-3-101

EMC shielding: Approx. 20dB(A) at 2 GHz without shielding material. >40dB(A) at 1 GHz with addition of stainless steel gasket between front panel and case body

LES CARACTÉRISTIQUES TECHNIQUES

Table 1/2

Référence catalogue	Rack Height	Profondeur	Usable Width	Montage	Conformité à	EMC Shielding
20860-122	1 U	340 mm	447 mm	Rack	IEC 60297-3-100, IEC 60297-3-105	No (Retrofittable)
20860-120	1 U	220 mm	447 mm	Rack	IEC 60297-3-100, IEC 60297-3-105	No (Retrofittable)
20860-121	1 U	280 mm	447 mm	Rack	IEC 60297-3-100, IEC 60297-3-105	No (Retrofittable)
20860-127	2 U	340 mm	447 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-126	2 U	280 mm	447 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Table 2/2

Référence catalogue	Product Family	Product Type	Type
20860-122	MultipacPRO	Subrack/Chassis	Plein
20860-120	MultipacPRO	Subrack/Chassis	Plein
20860-121	MultipacPRO	Subrack/Chassis	Plein
20860-127	MultipacPRO	Subrack/Chassis	Plein
20860-126	MultipacPRO	Subrack/Chassis	Plein

ADDITIONAL PRODUCT DETAILS

Please order front handles separately.

Telescopic slides cannot be used.

Further versions with steel front panel (pizza box) available on request.

Standardised internal mounting kits cannot be used.

AVERTISSEMENT

Les produits nVent doivent être installés et utilisés conformément aux consignes figurant dans les fiches d'instructions et les documents de formation des produits nVent. Les fiches d'instructions sont disponibles à l'adresse suivante : www.nvent.com et auprès de votre représentant du service client nVent. Une mauvaise installation, une utilisation incorrecte,

une application erronée ou toute autre forme de non-respect scrupuleux des instructions et avertissements de nVent peuvent entraîner un dysfonctionnement du produit, des dommages matériels, des lésions corporelles graves et le décès et/ou annuler votre garantie.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE